


MULTIPLES OF CURRENT RATING

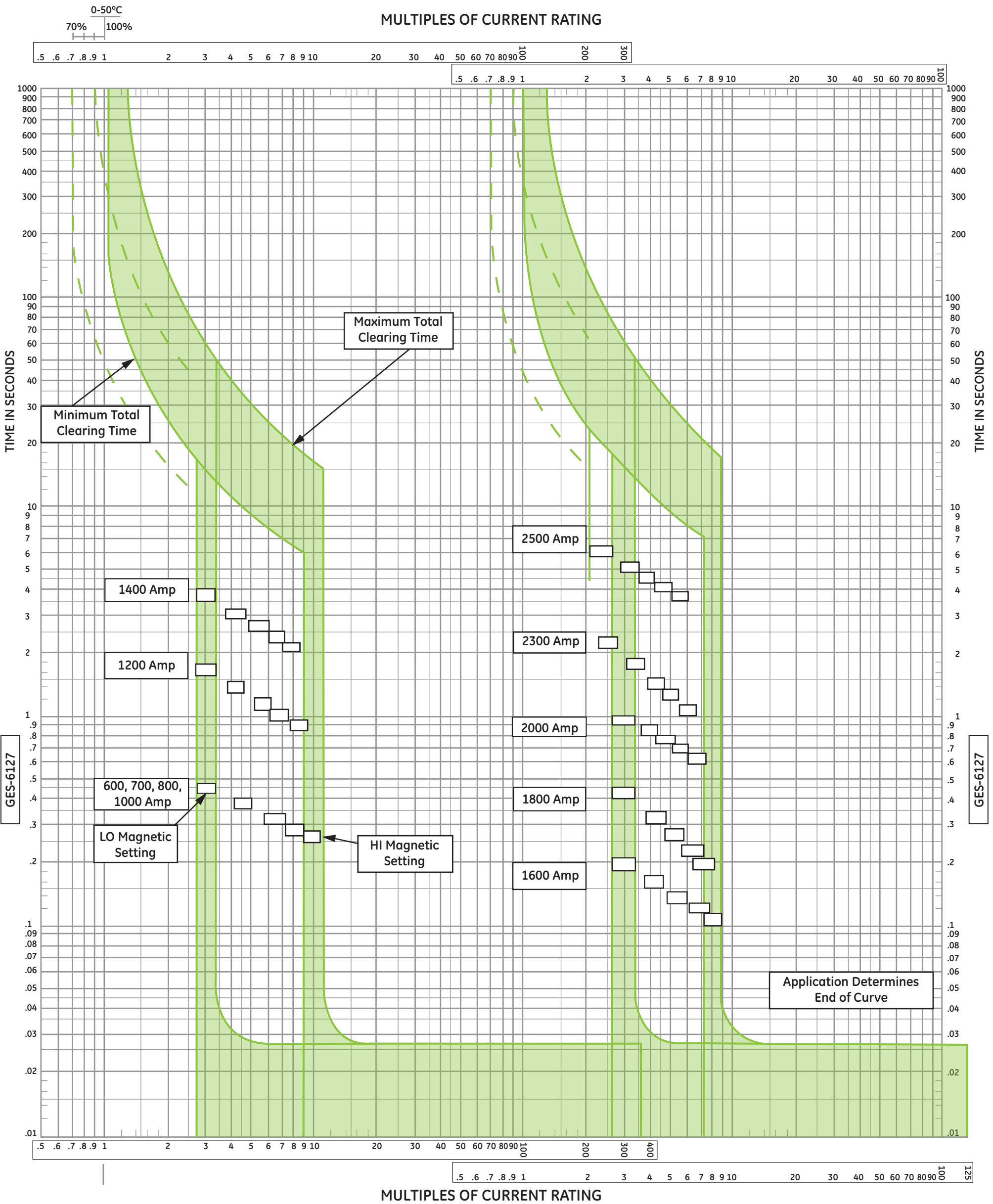

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

600, 700, 800, 1000, 1200, 1400, 1600,
1800, 2000, 2300 and 2500 Amperes

Voltage Ratings

600 Vac, 250 Vdc

Frequency Rating

60 Hertz

**Molded Case Circuit Breaker
POWER BREAK™**

Type THS (2000A & 2500A Frame)
Long-time Delay and Instantaneous
Time-current Curves

Curves show circuit breaker in open air, 0°C
to 50°C ambient, wired with conductors of
corresponding rating, no prior load.


GES-6127

Adjustments

Standard long-time magnetic delay, 100% of rating,
not adjustable. Optional THS adjustable trip, 70-100%
of rating.

Instantaneous magnetic trip, continuous adjustment,
factory set on HI.

Blocks show trip range at each setting.

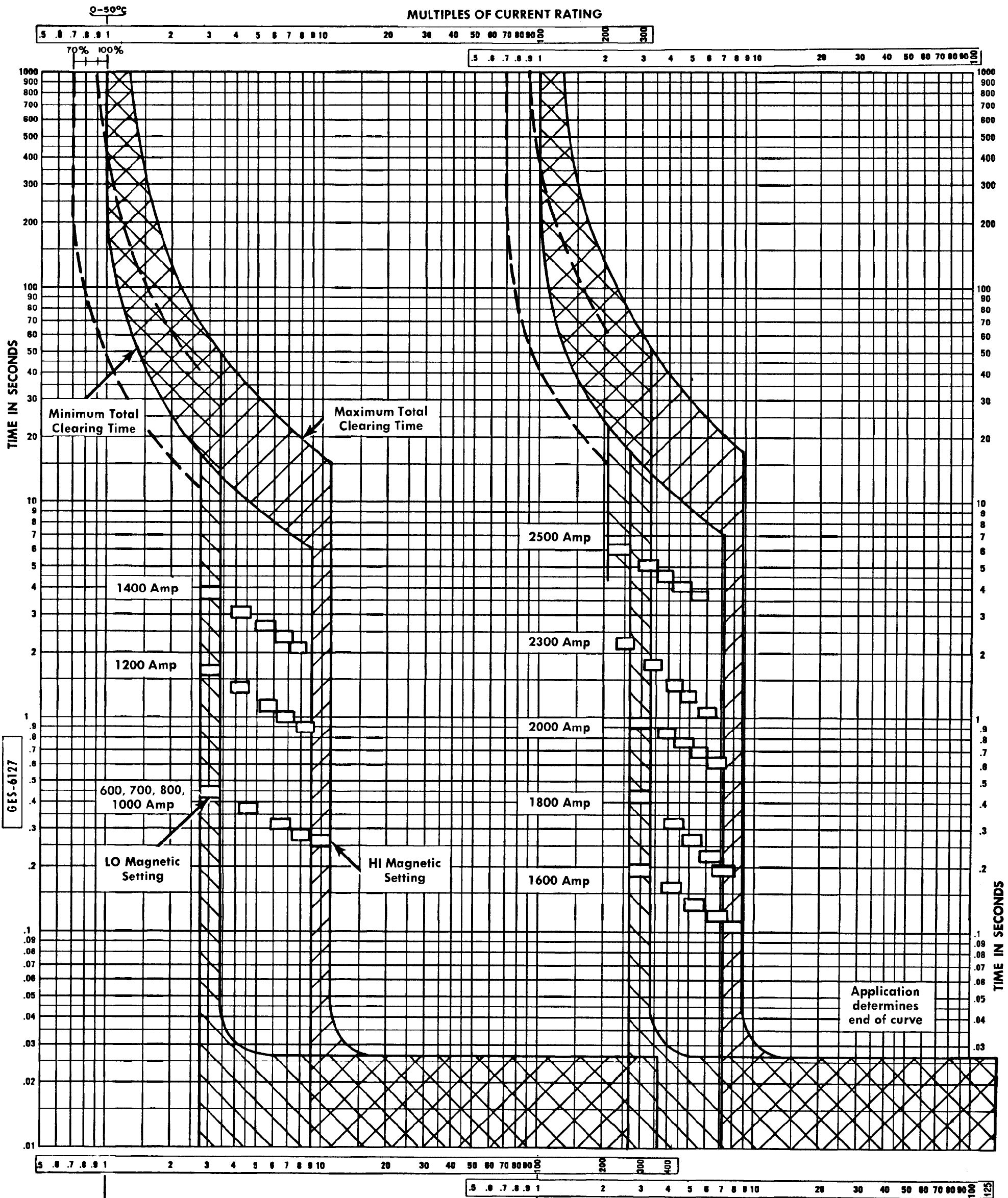

MULTIPLES OF CURRENT RATING

GENERAL ELECTRIC

Current Ratings
600, 700, 800, 1000, 1200, 1400, 1600,
1800, 2000, 2300, and 2500 amperes

Voltage Ratings
600 volts a-c, 250 volts d-c

Frequency Ratings
60 Hertz

MOLDED-CASE CIRCUIT BREAKER

POWER BREAK™

Type THS (2000A & 2500A Frame)

Long-time Delay and Instantaneous Time-current Curves

(Curves show circuit breaker in open air, 0-50 C ambient, wired with conductors of corresponding rating, no prior load.)

GES-6127

Adjustments

Standard long-time magnetic delay, 100% of rating, not adjustable. Optional THS adjustable trip, 70-100% of rating.

Instantaneous magnetic trip, continuous adjustment, factory set on HI.

Blocks show trip range at each setting.