

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

2000, 2500 and 3000 Amperes

Voltage Ratings

600 Vac, 250 Vdc

Frequency Rating

60 Hertz

**Molded Case Circuit Breaker
POWER BREAK™**

Type THS (3000A Frame)
Long-time Delay and Instantaneous
Time-current Curves

Curves show circuit breaker in open air, 0°C
to 50°C ambient, wired with conductors of
corresponding rating, no prior load.

GES-6128

Adjustments


Standard long-time magnetic delay, 100% of rating,
not adjustable. Optional THS adjustable trip, 70-100%
of rating.

Instantaneous magnetic trip, continuous adjustment,
factory set on HI.

Blocks show trip range at each setting.

0-50°C

MULTIPLES OF CURRENT RATING

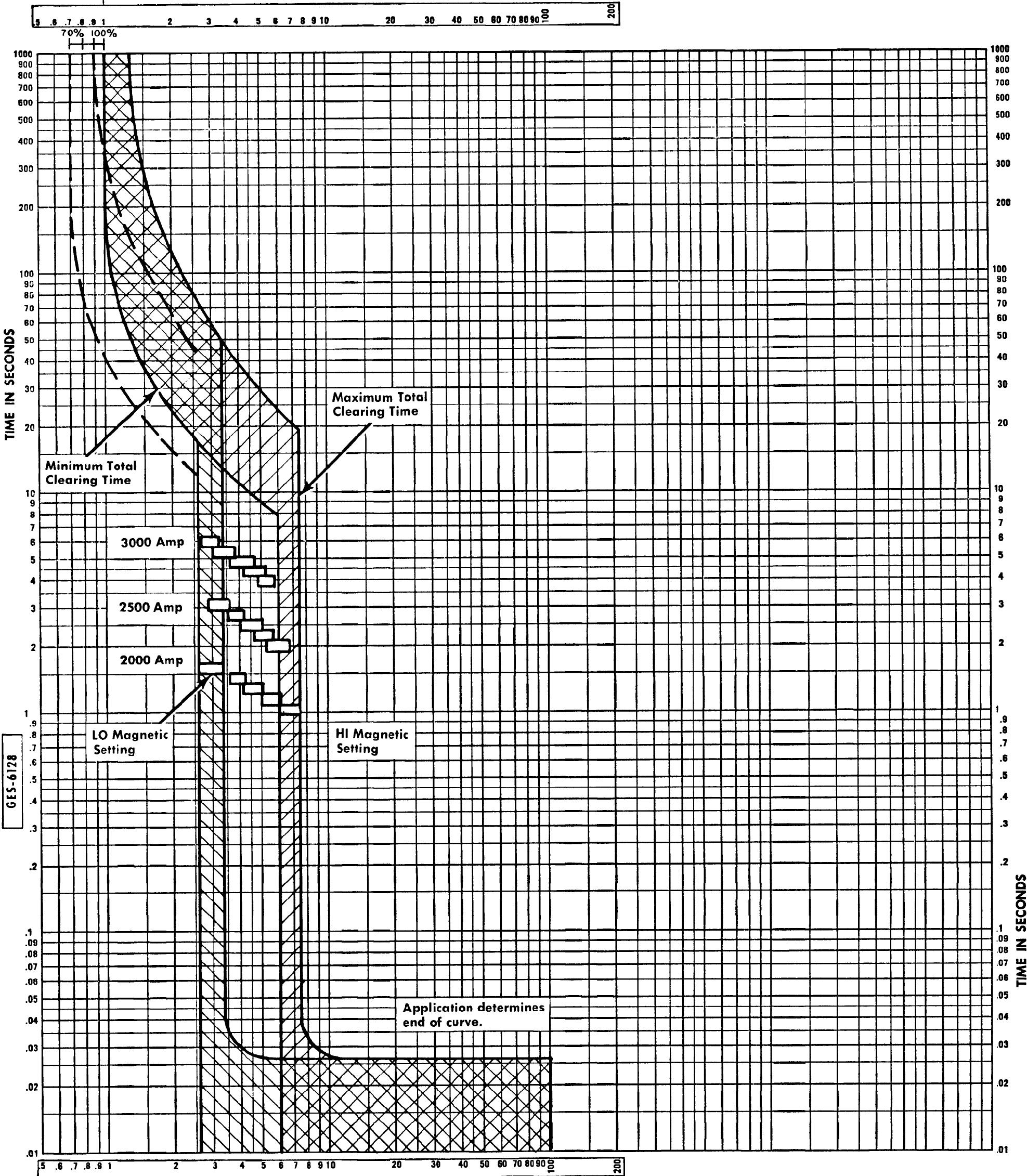

MULTIPLES OF CURRENT RATING

<p>GENERAL ELECTRIC</p>	<p>MOLDED-CASE CIRCUIT BREAKER POWER BREAK™ Type THS (3000A Frame)</p>	<p>GES-6128</p>
<p>Current Ratings 2000, 2500 and 3000 amperes</p> <p>Voltage Ratings 600 volts a-c, 250 volts d-c</p> <p>Frequency Rating 60 Hertz</p>	<p>Long-time Delay and Instantaneous Time-current Curves</p> <p>(Curves show circuit breaker in open air, 0-50 C ambient, wired with conductors of corresponding rating, no prior load.)</p>	<p>Adjustments</p> <p>Standard long-time magnetic delay, 100% of rating, not adjustable. Optional THS adjustable trip, 70-100% of rating.</p> <p>Instantaneous magnetic trip, continuous adjustment, factory set on HI.</p> <p>Blocks show trip range at each setting.</p>