


MULTIPLES OF CURRENT RATING

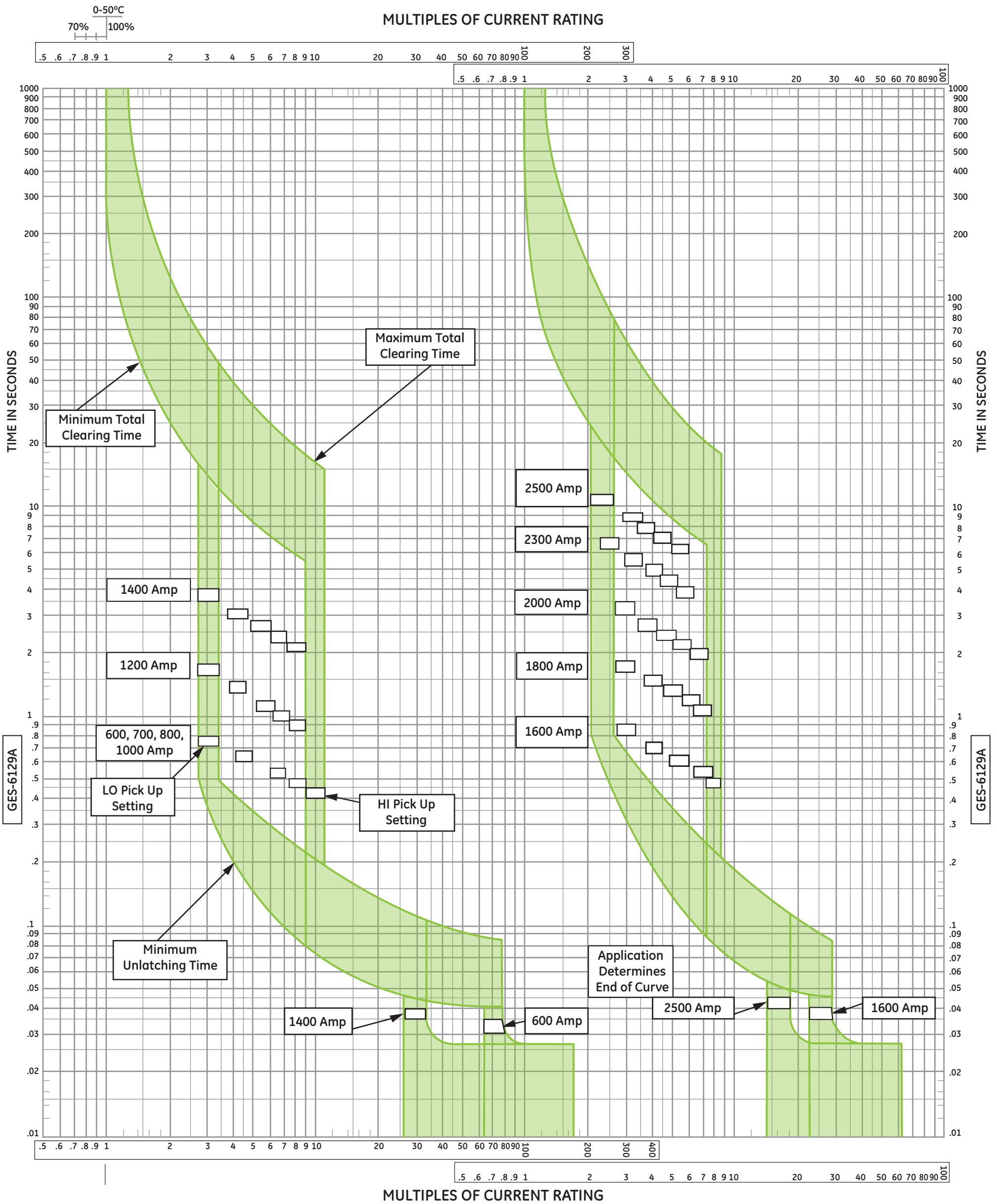

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

600, 700, 800, 1000, 1200, 1400, 1600,
1800, 2000, 2300 and 2500 Amperes

Voltage Ratings

600 Vac, 250 Vdc

Frequency Rating

60 Hertz

**Molded Case Circuit Breaker
POWER BREAK™**


Type TPS (2000A & 2500A Frame)
Long-time Delay, Short-time Delay
and Instantaneous Time-current Curves

Curves show circuit breaker in open air, 0°C
to 50°C ambient, wired with conductors of
corresponding rating, no prior load.

GES-6129A

Adjustments

Long-time magnetic delay, not adjustable.
Short-time magnetic delay, adjustable pickup as
indicated by blocks shown for each setting.
Instantaneous magnetic trip, fixed 42,000 sym
amperes irrespective of trip unit rating.

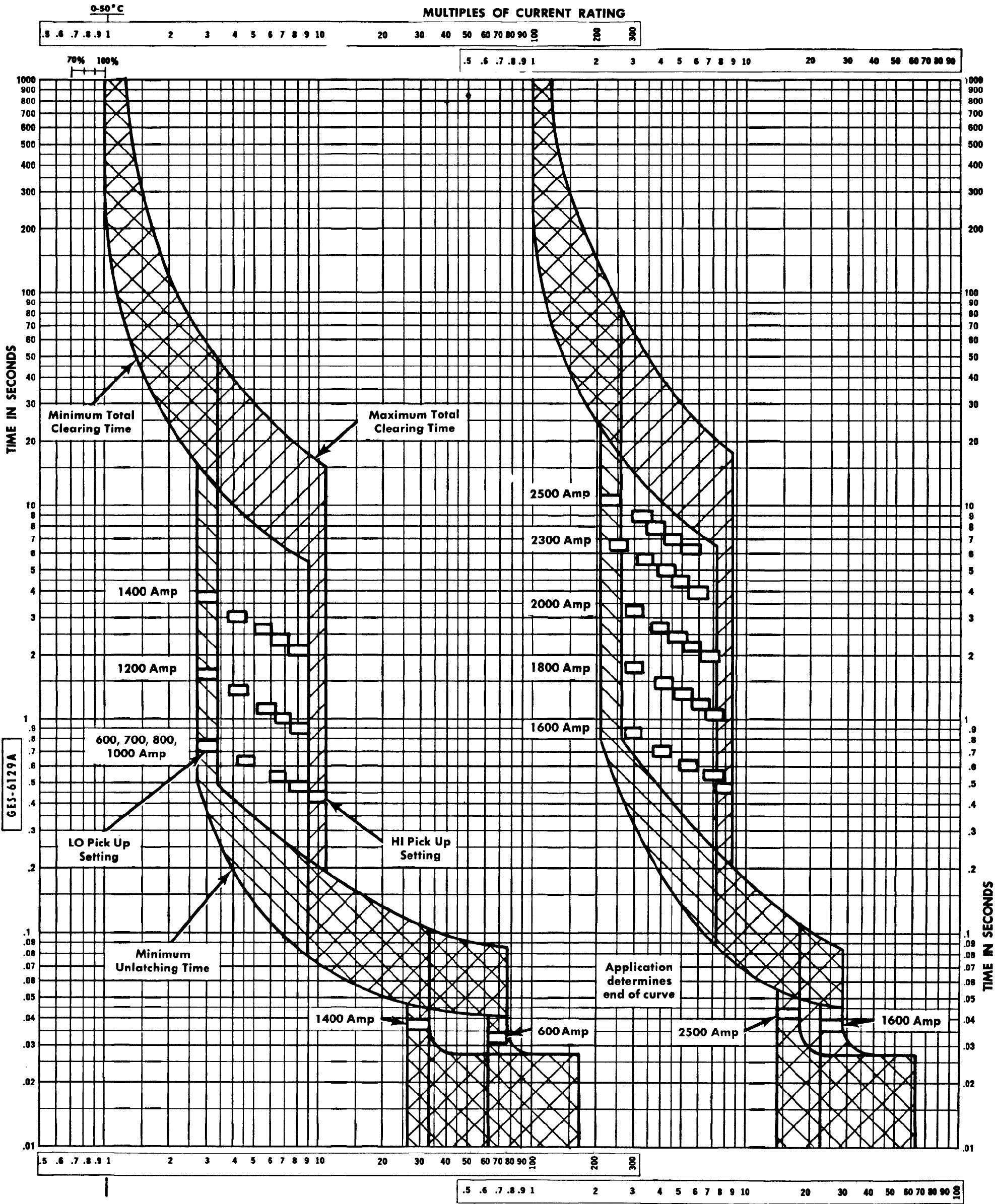

MULTIPLES OF CURRENT RATINGS

<p>GENERAL ELECTRIC</p> <p>Current Ratings 600, 700, 800, 1000, 1200, 1400, 1600, 1800, 2000, 2300, and 2500 amperes</p> <p>Voltage Ratings 600 volts ac, 250 volts dc</p> <p>Frequency Ratings 60 Hertz</p>	<p>MOLDED-CASE CIRCUIT BREAKER</p> <p>POWER BREAK™</p> <p>Type TPS (2000A & 2500A Frame)</p> <p>Long-time Delay, Short-time Delay and Instantaneous Time-current Curves</p> <p>(Curves show circuit breaker in open air, 0-50°C ambient, wired with conductors of corresponding rating, no prior load.)</p>	<p>GES-6129A</p> <p>Adjustments</p> <p>Long-time magnetic delay, not adjustable.</p> <p>Short-time magnetic delay, adjustable pick up as indicated by blocks shown for each setting.</p> <p>Instantaneous magnetic trip, fixed 42,000 sym amperes irrespective of trip unit rating.</p>
--	--	---