


0-50°C

MULTIPLES OF CURRENT RATING

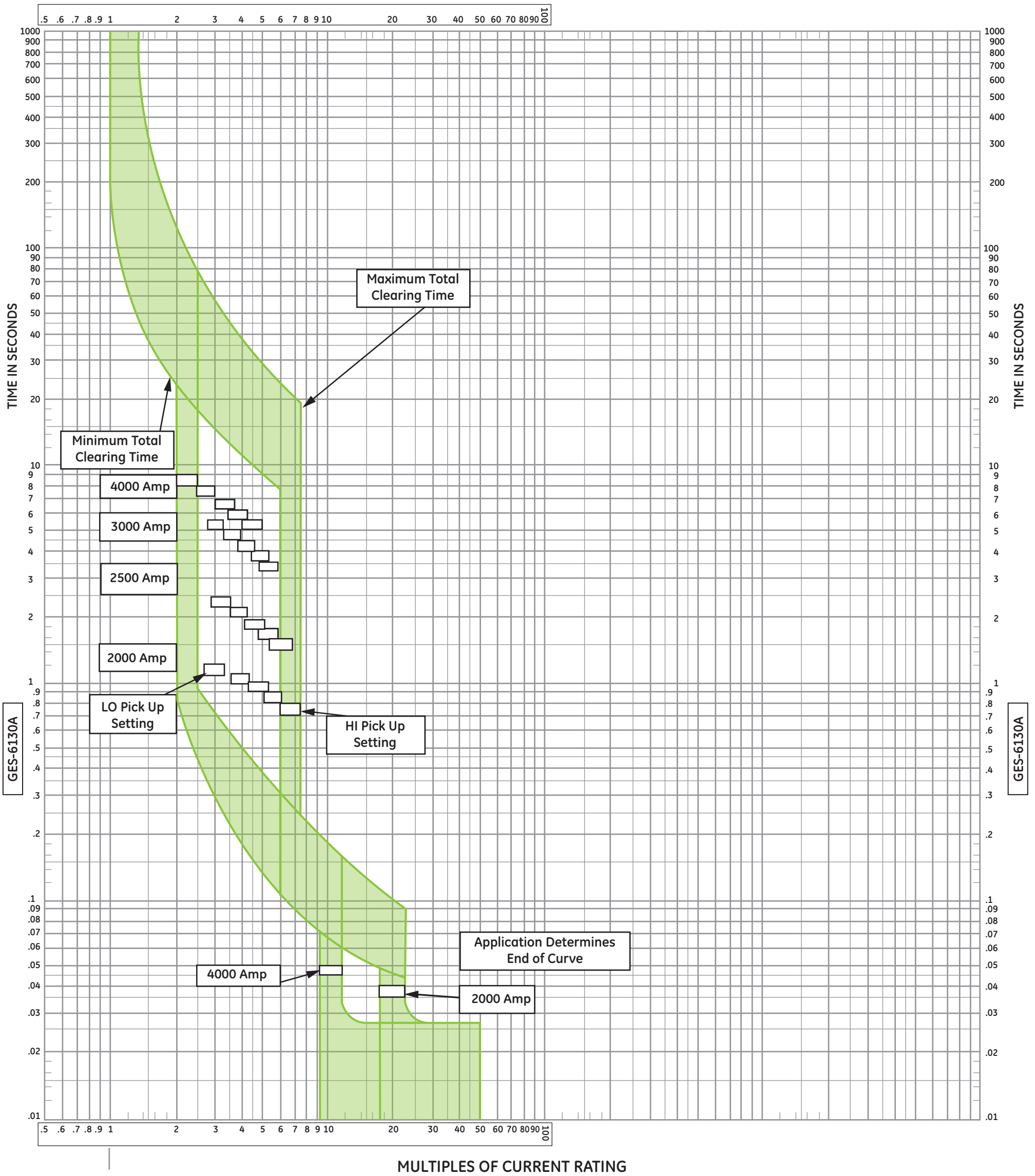

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

3000A Frame — 2000, 2500 and 3000
Amperes

4000A Breaker — 4000 Amperes

Voltage Ratings

600 Vac, 250 Vdc

Frequency Rating

60 Hertz

Molded Case Circuit Breaker POWER BREAK™

Type TPS
(3000A Frame & 4000A Breaker)
Long-time Delay, Short-time Delay and
Instantaneous Time-current Curves

Curves show circuit breaker in open air, 0°C
to 50°C ambient, wired with conductors of
corresponding rating, no prior load.

GES-6130A

Adjustments

Long-time magnetic delay, not adjustable.


Short-time magnetic delay, adjustable pick up as
indicated by blocks shown for each setting.

Instantaneous magnetic trip, fixed 42,000 sym
amperes irrespective of trip unit rating.

MULTIPLES OF CURRENT RATING

5 6 7 8 9 10 20 30 40 50 60 70 80 90 100

0-50°C

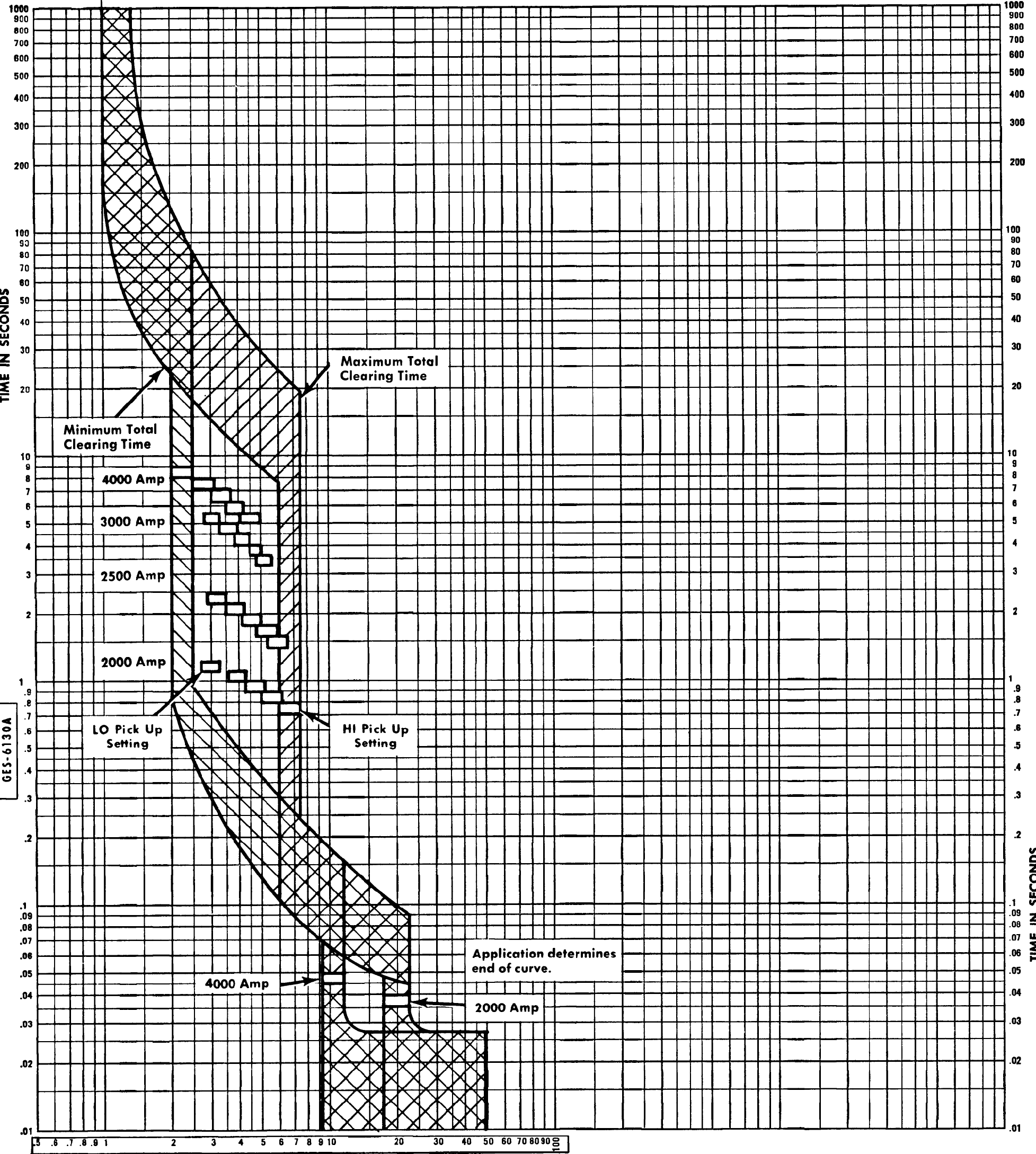

MULTIPLES OF CURRENT RATING

GENERAL ELECTRIC

Current Ratings
 3000A Frame — 2000, 2500 and 3000 amperes
 4000A Breaker — 4000 amperes

Voltage Ratings
 600 volts a-c, 250 volts d-c

Frequency Rating
 60 Hertz

MOLDED-CASE CIRCUIT BREAKER

POWER BREAK™

Type TPS (3000A Frame & 4000A Breaker)

Long-time Delay, Short-time Delay and Instantaneous Time-current Curves

(Curves show circuit breaker in open air, 0-50 C ambient, wired with conductors of corresponding rating, no prior load.)

GES-6130A

Adjustments

Long-time magnetic delay, not adjustable.
 Short-time magnetic delay, adjustable pick up as indicated by blocks shown for each setting.
 Instantaneous magnetic trip, fixed 42,000 sym amperes irrespective of trip unit rating.