


MULTIPLES OF CURRENT RATING

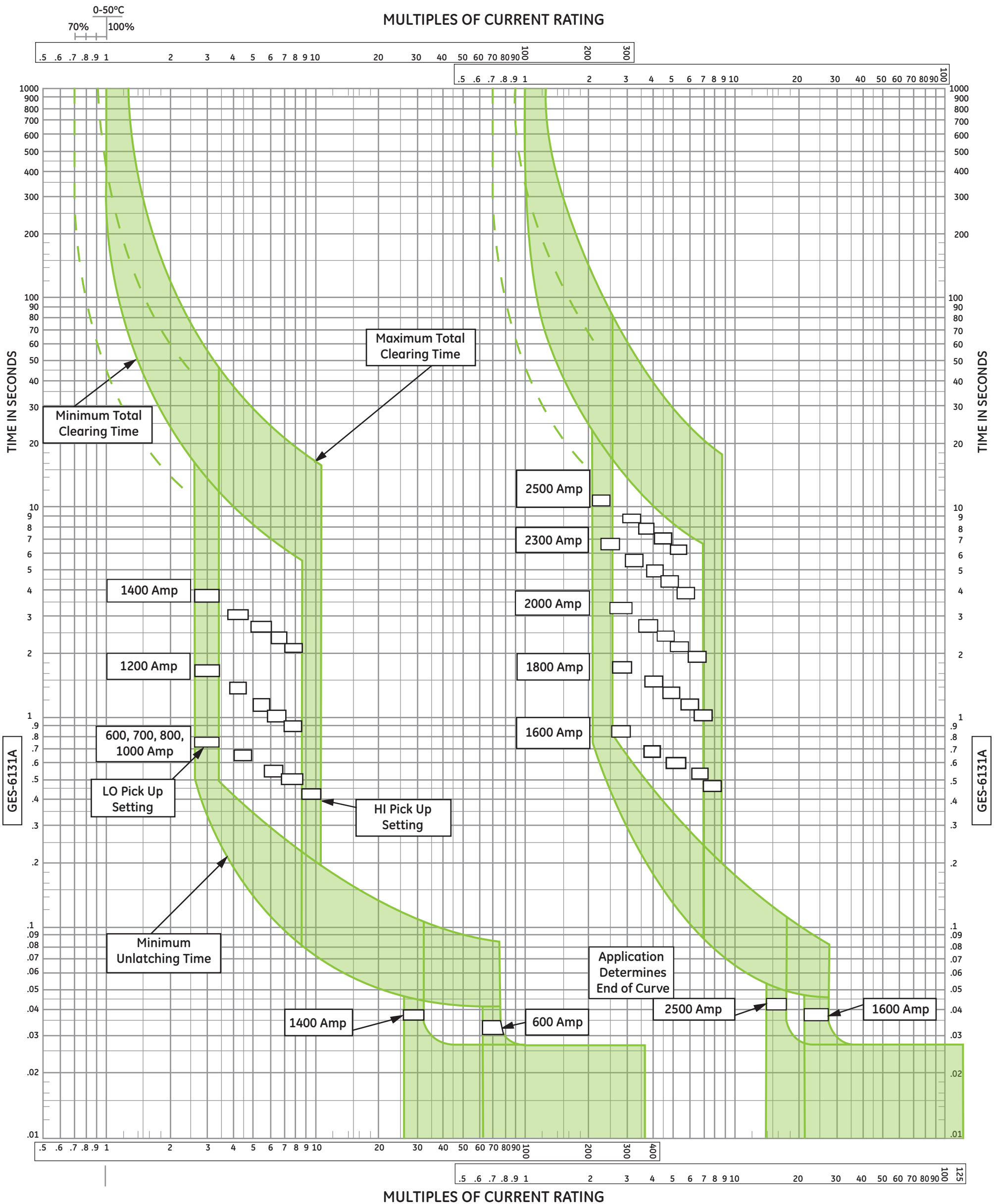

GE Consumer & Industrial -  
Electrical Distribution

**Current Ratings**

600, 700, 800, 1000, 1200, 1400, 1600,  
1800, 2000, 2300 and 2500 Amperes

**Voltage Ratings**

600 Vac, 250 Vdc

**Frequency Rating**

60 Hertz

**Molded Case Circuit Breaker  
POWER BREAK™**

Type THS (2000A & 2500A Frame)  
Long-time Delay, Short-time Delay  
and Instantaneous Time-current Curves

Curves show circuit breaker in open air, 0°C  
to 50°C ambient, wired with conductors of  
corresponding rating, no prior load.


**GES-6131A**

**Adjustments**

Standard long-time magnetic delay, 100% of rating,  
not adjustable. Optional THS adjustable trip, 70-100%  
of rating.

Short-time magnetic delay, adjustable pickup as  
indicated by blocks shown for each setting.

Instantaneous magnetic trip, fixed 42,000 sym  
amperes irrespective of trip unit rating.

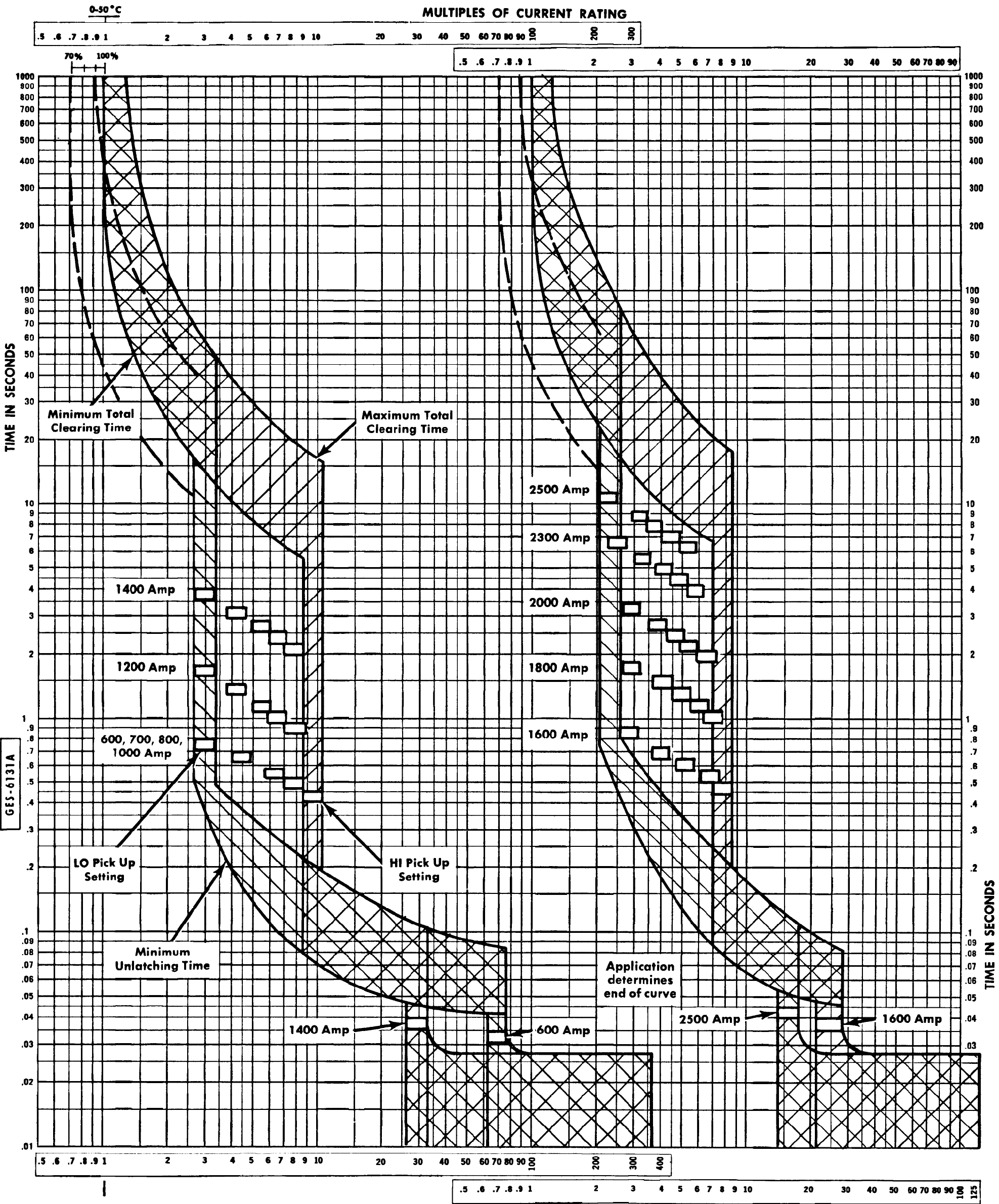

**GENERAL ELECTRIC**

**Current Ratings**  
600, 700, 800, 1000, 1200, 1400, 1600,  
1800, 2000, 2300, and 2500 amperes

**Voltage Ratings**  
600 volts a-c, 250 volts d-c

**Frequency Ratings**  
60 Hertz

**MOLDED-CASE CIRCUIT BREAKER**

**POWER BREAK™**

Type THS (2000A & 2500A Frame)

**Long-time Delay, Short-time Delay and  
Instantaneous Time-current Curves**

(Curves show circuit breaker in open air, 0-50°C  
ambient, wired with conductors of corresponding  
rating, no prior load.)

**GES-6131A**

**Adjustments**

Standard long-time magnetic delay, 100% of rat-  
ing, not adjustable. Optional THS adjustable trip,  
70-100% of rating.

Short-time magnetic delay, adjustable pickup  
as indicated by blocks shown for each setting.  
Instantaneous magnetic trip, fixed 42,000 sym  
amperes irrespective of trip unit rating.