


MULTIPLES OF AMPERE SETTING (CONTINUOUS)

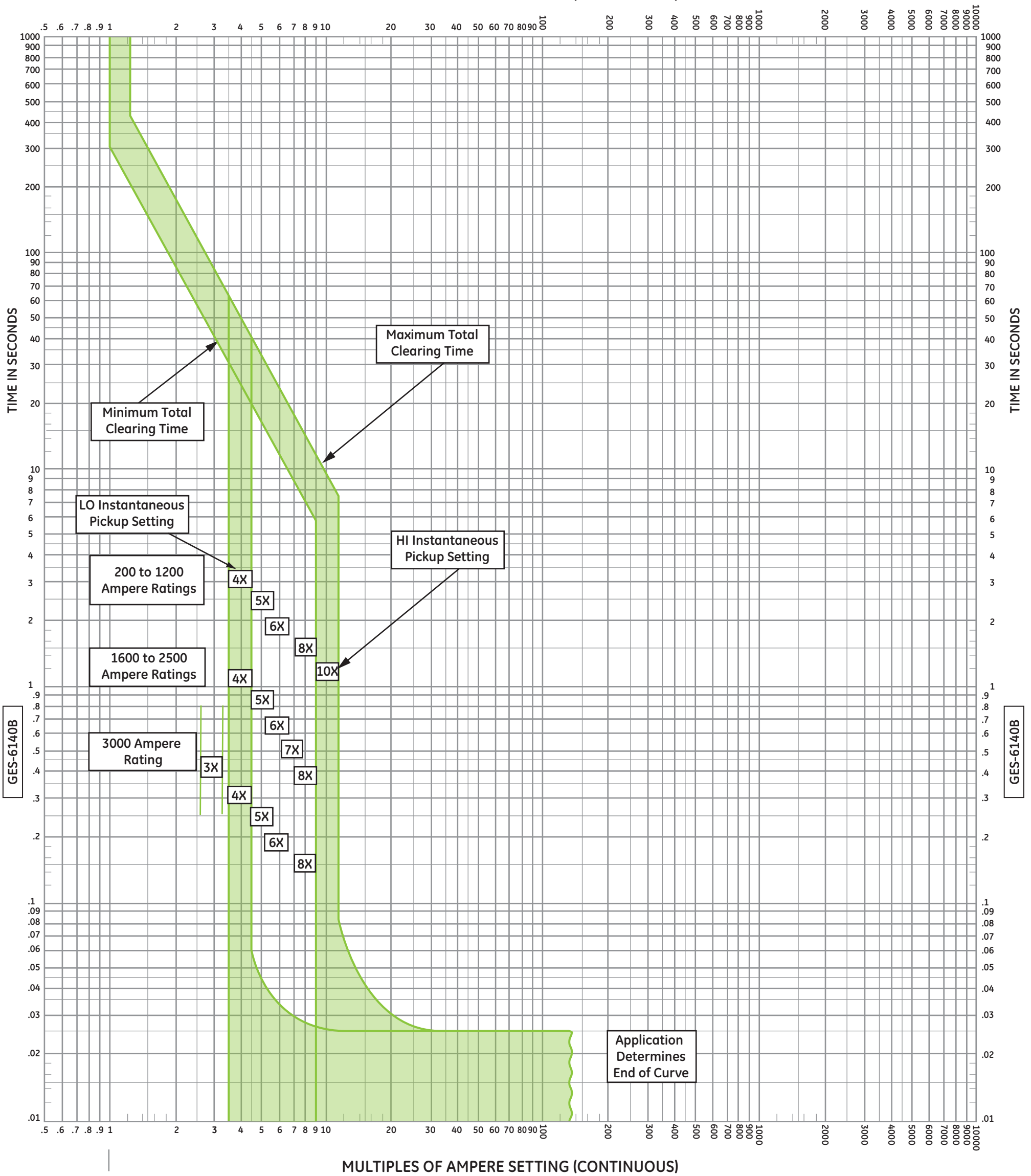

GE Consumer & Industrial -
Electrical Distribution

Sensor Rating (Amperes)

200, 400, 600, 800, 1200, 1600, 2000,
2500, 3000 Amperes

Voltage Rating

600 Vac

Frequency Rating

50/60 Hertz

**Insulated-Case Circuit Breaker
POWER BREAK™ with SelecTrip™**

Types TPR, THR, TPRR, THRR

**Long-time and Instantaneous
Time-current Curves**

Curves apply at 50/60 Hertz and
from -20°C to +55°C breaker ambient.

GES-6140B

Adjustments

Long-time Delay Unit: Continuous current settings are
50, 60, 70, 80, 90 and 100% of sensor rating.

Instantaneous Unit: Pick-up current settings are 4X, 5X,
6X, 8X and 10X multiples of Long-time unit settings
thru 1200 amperes, 4X, 5X, 6X, 7X and 8X for 1600 to
2500 amperes and 3X, 4X, 5X, 6X and 8X for 3000
ampere ratings.