


GROUND FAULT CURRENT IN AMPERES

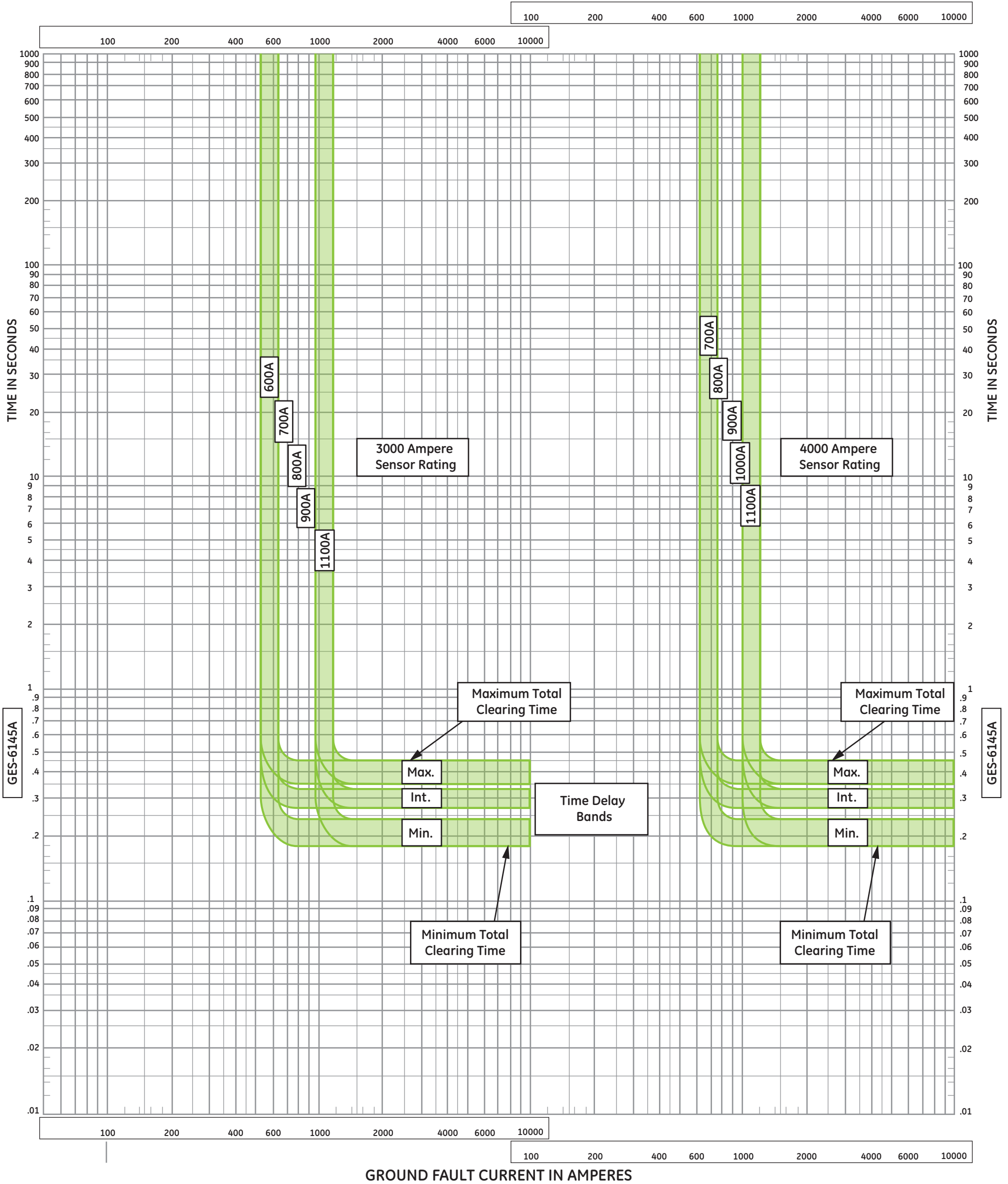

GE Consumer & Industrial -
Electrical Distribution

Sensor Rating
3000, 4000 Amperes

Voltage Rating
600 Vac

Frequency Rating
50/60 Hertz

**Insulated-Case Circuit Breaker
POWER BREAK® with VersaTrip®**

Types TPSS, THSS
Ground Fault Pickup Settings
and Delay Time-current Curves

Curves apply at 50/60 Hertz and
from -20°C to +55°C breaker ambient.

GES-6145A

Adjustments

Ground Fault Unit: Pick-up current settings are 600, 700, 800, 900, and 1100A for 3000A sensor rating, and 700, 800, 900, 1000, and 1100A for 4000A sensor rating. Time-delay bands are maximum, intermediate, and minimum.