

GE Consumer & Industrial -  
Electrical Distribution

**Current Ratings**

1600A Frame — 1600 amperes  
1200A Frame — 200, 400, 600, 800, 1000,  
and 1200 amperes

**Voltage Ratings**

600 Vac, 250 Vdc

**Frequency Rating**

50/60 Hertz

**Insulated Case Circuit Breaker  
POWER BREAK™ with MagneTrip™**

Types TPMM, THMM  
Long-time Delay and Instantaneous  
Time-current Curves

Curves show circuit breaker in open air, 0°C  
to 50°C ambient, wired with conductors of  
corresponding rating, no prior load.


**GES-6164**

**Adjustments**

Long-time trip: Current setting is continuously  
adjustable 70-100% of nameplate rating. Long-time  
delay varies with current setting as shown above.

Instantaneous trip: Continuous adjustment, factory  
set on HI. Pickup setting.

Blocks show trip range at each setting.

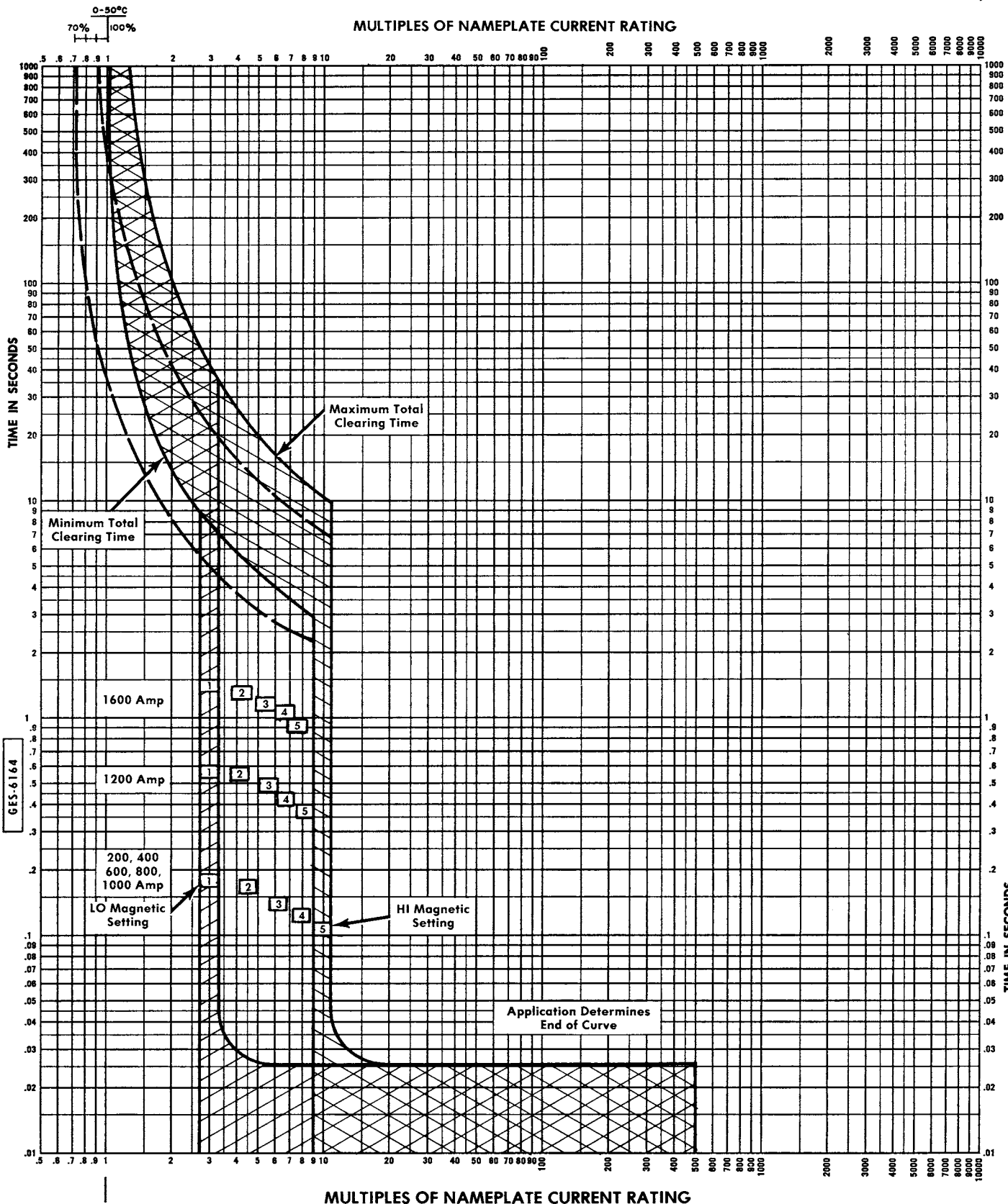

**GE Electrical Distribution & Control**

**Current Ratings**  
1600A Frame — 1600 amperes  
1200A Frame — 200, 400, 500, 800, 1000 and 1200 amperes

**Voltage Ratings**  
600 volts ac, 250 volts dc

**Frequency Rating**  
50/60 Hertz

**INSULATED CASE CIRCUIT BREAKER POWER BREAK™ With MagneTrip™**

**Types TPMM, THMM**

**Long-time Delay and Instantaneous Time-current Curves**

(Curves show circuit breaker in open air, 0°C to 50°C ambient, wired with conductors of corresponding rating, no prior load.)

**GE-6164**

**Adjustments**

Long-time trip: Current setting is continuously adjustable 70-100% of nameplate rating. Long-time delay varies with current setting as shown above. Instantaneous trip: Continuous adjustment, factory set on HI. Pickup setting. Blocks show trip range at each setting.

**GE Electrical Distribution & Control 41 Woodford Ave. Plainville, CT 06062**