

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

3000A Frame — 3000 Amperes

4000A Frame — 3000, 4000 Amperes

Voltage Ratings

600 Vac, 250 Vdc

Frequency Ratings

50/60 Hertz

**Insulated Case Circuit Breaker
POWER BREAK® with MagneTrip™**

Types TPMM, THMM
Long-time Delay and Instantaneous
Time-current Curves

Curves show circuit breaker in open air, 0°C
to 50°C ambient, wired with conductors of
corresponding rating, no prior load.

GES-6167A


Adjustments

Long-time trip: Current setting is continuously
adjustable 70-100% of nameplate rating. Long-time
delay varies with current setting as shown above.

Instantaneous trip: Continuous adjustment, factory
set on HI. Pickup setting.

Blocks show trip range at each setting.

MULTIPLES OF NAMEPLATE CURRENT RATING

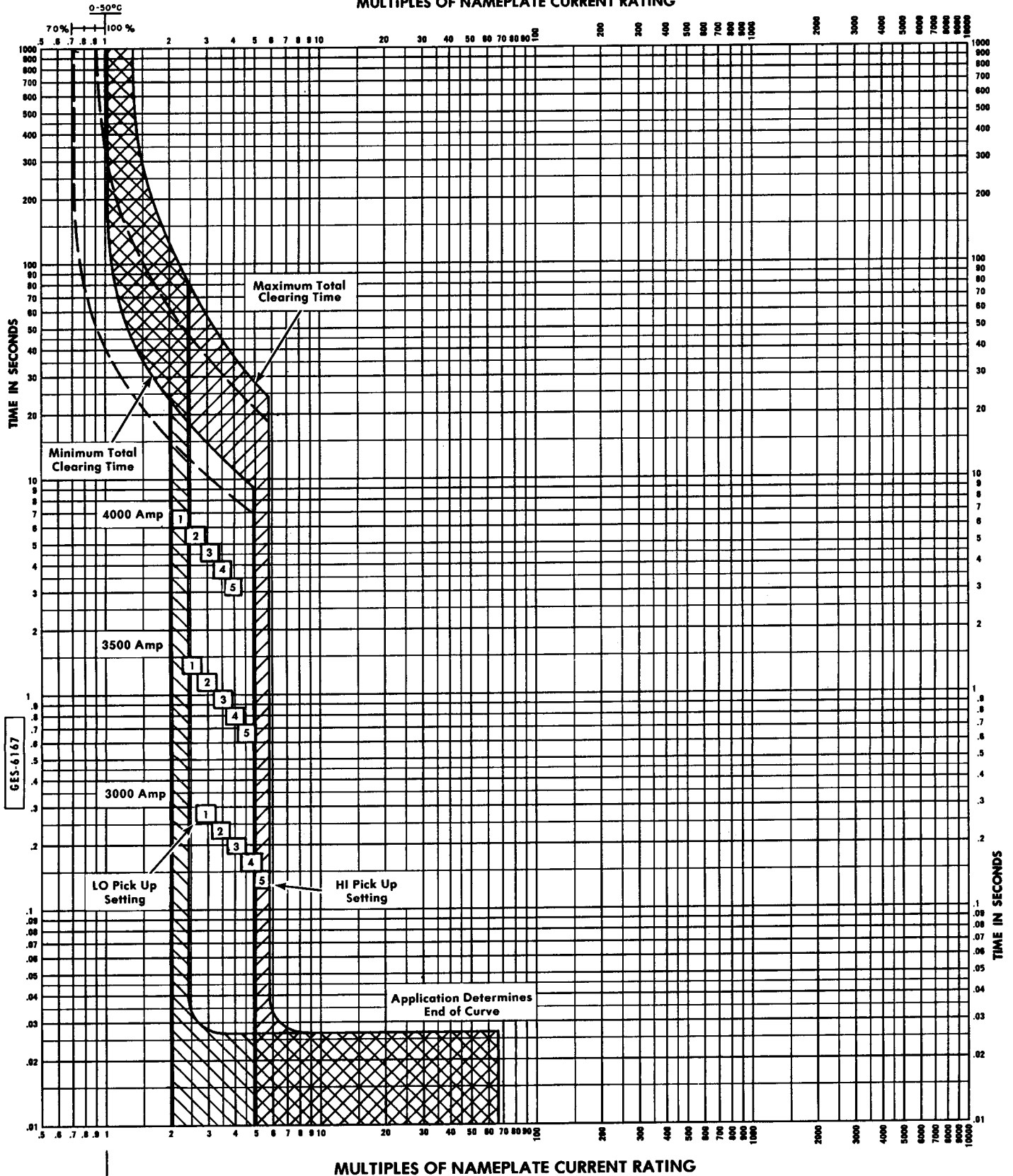

MULTIPLES OF NAMEPLATE CURRENT RATING



GE Electrical Distribution & Control

General Electric Company
41 Woodford Avenue, Plainville, CT 06062

Current Ratings
3000A Frame - 3000 Amperes
4000A Frame - 3000, 4000 Amperes

Voltage Ratings
600 Volts ac (250 Volts dc)

Frequency Ratings
50/60 Hertz

Insulated Case Circuit Breaker

POWER BREAK®

With MagneTrip™

Types TPMM, THMM

Long Time Delay and Instantaneous Time Current Curves

Curves show circuit breaker in open air, 0°-50°C ambient, wired with conductors of corresponding rating, no prior load.

GES-6167A

Legend Revision Only

Adjustments

Long Time Trip: Current setting is continuously adjustable 70-100% of nameplate rating. Long time delay varies with current setting as shown above.

Instantaneous Trip: Continuous adjustment, factory set on HI. Pickup setting.

Blocks show trip range at each setting.