

**GE Consumer & Industrial -
Electrical Distribution**

Current Rating
2500 Amperes

Voltage Ratings
600 Vac, 250 Vdc

Frequency Ratings
50/60 Hertz

Insulated Case Circuit Breaker POWER BREAK® with MagneTrip™

Types TPMM, THMM
Long-time Delay, Short-time Delay
and Instantaneous Time-current Curves

Curves show circuit breaker in open air, 0°C
to 50°C ambient, wired with conductors of
corresponding rating, no prior load.

GES-6170


Adjustments

Long-time trip: Current setting is continuously
adjustable 70-100% of nameplate rating. Long-time
delay varies with current setting as shown above.

Short-time delay: Adjustable pickup as indicated by
blocks shown for each setting.

Instantaneous trip: Fixed 42,000 sym amperes.

MULTIPLES OF NAMEPLATE CURRENT RATING

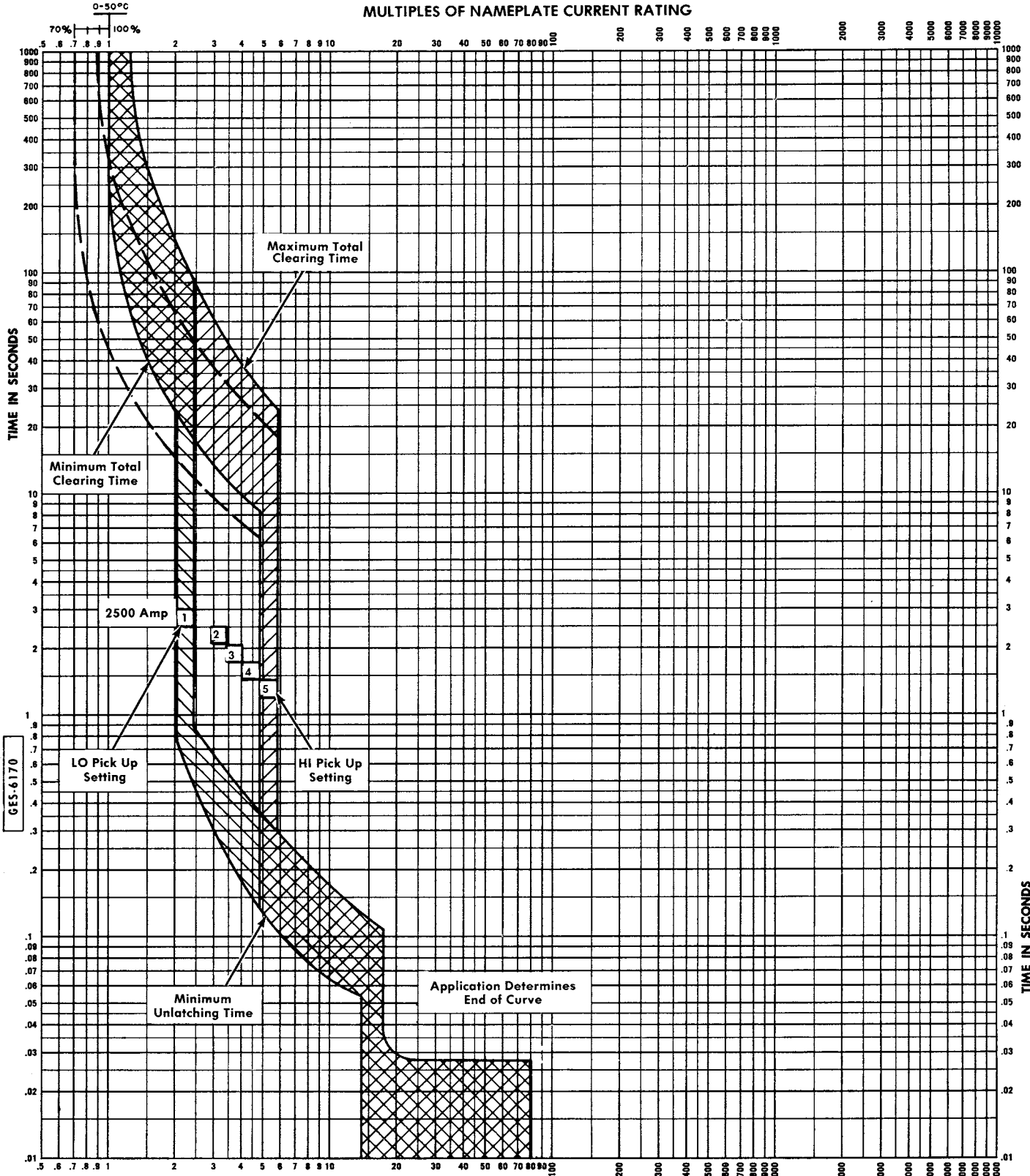

MULTIPLES OF NAMEPLATE CURRENT RATING



**GE Electrical
Distribution & Control**

Current Rating
2500 amperes
Voltage Ratings
600 volts ac, 250 volts dc
Frequency Ratings
50/60 Hertz

**INSULATED CASE CIRCUIT BREAKER
POWER BREAK™
With MagneTrip™
Types TPMM, THMM**

**Long-time Delay, Short-time Delay and
Instantaneous Time-current Curves**

(Curves show circuit breaker in open air, 0°C to 50°C ambient, wired with conductors of corresponding rating, no prior load.)

GES-6170

Adjustments

Long-time trip: Current setting is continuously adjustable 70-100% of nameplate rating. Long-time delay varies with current setting as shown above. Short-time delay: Adjustable pickup as indicated by blocks shown for each setting. Instantaneous trip: Fixed 42,000 sym amperes.

GE Electrical Distribution & Control 41 Woodford Ave. Plainville, CT 06062