


MULTIPLES OF SENSOR AMPERE RATING

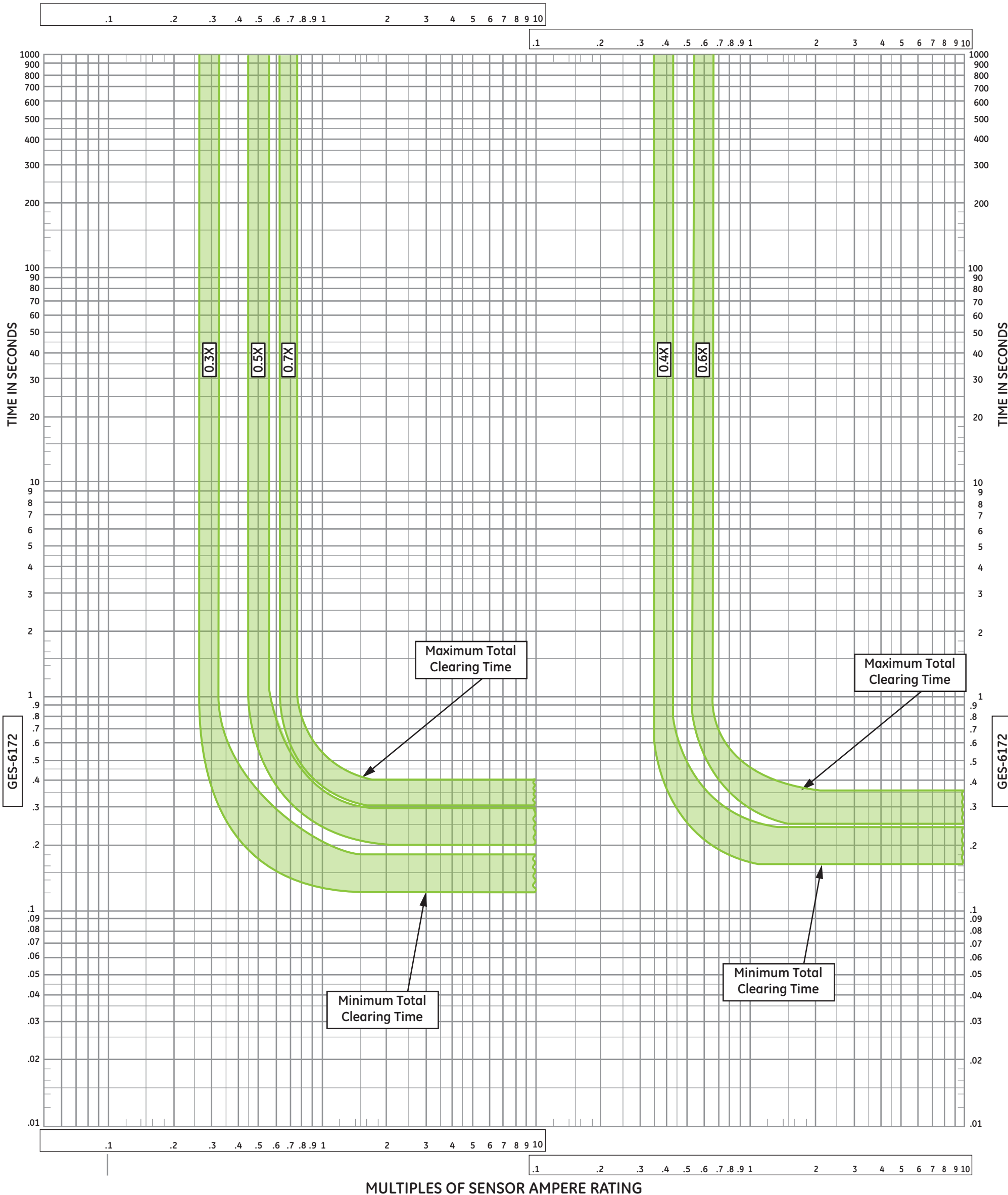

GE Consumer & Industrial -  
Electrical Distribution

**Sensor Rating (Amperes)**  
800, 1000, 1200, 1600 Amperes

**Voltage Rating**  
600 Vac

**Frequency Rating**  
50/60 Hertz

**Insulated-Case Circuit Breaker  
POWER BREAK® with SelecTrip™**

Types TPR, THR, TPRR, THRR  
Ground Fault Pickup Settings  
and Delay Time-current Curves


Curves apply at 50/60 Hertz and  
from -20°C to +55°C breaker ambient.

**GES-6172**

**Adjustments**

Ground Fault Unit: Pick-up current settings are 0.3x, 0.4x, 0.5x, 0.6x, and 0.7x of breaker sensor ampere rating. Time-delay bands vary with pick-up current setting as shown above.

MULTIPLES OF SENSOR AMPERE RATING

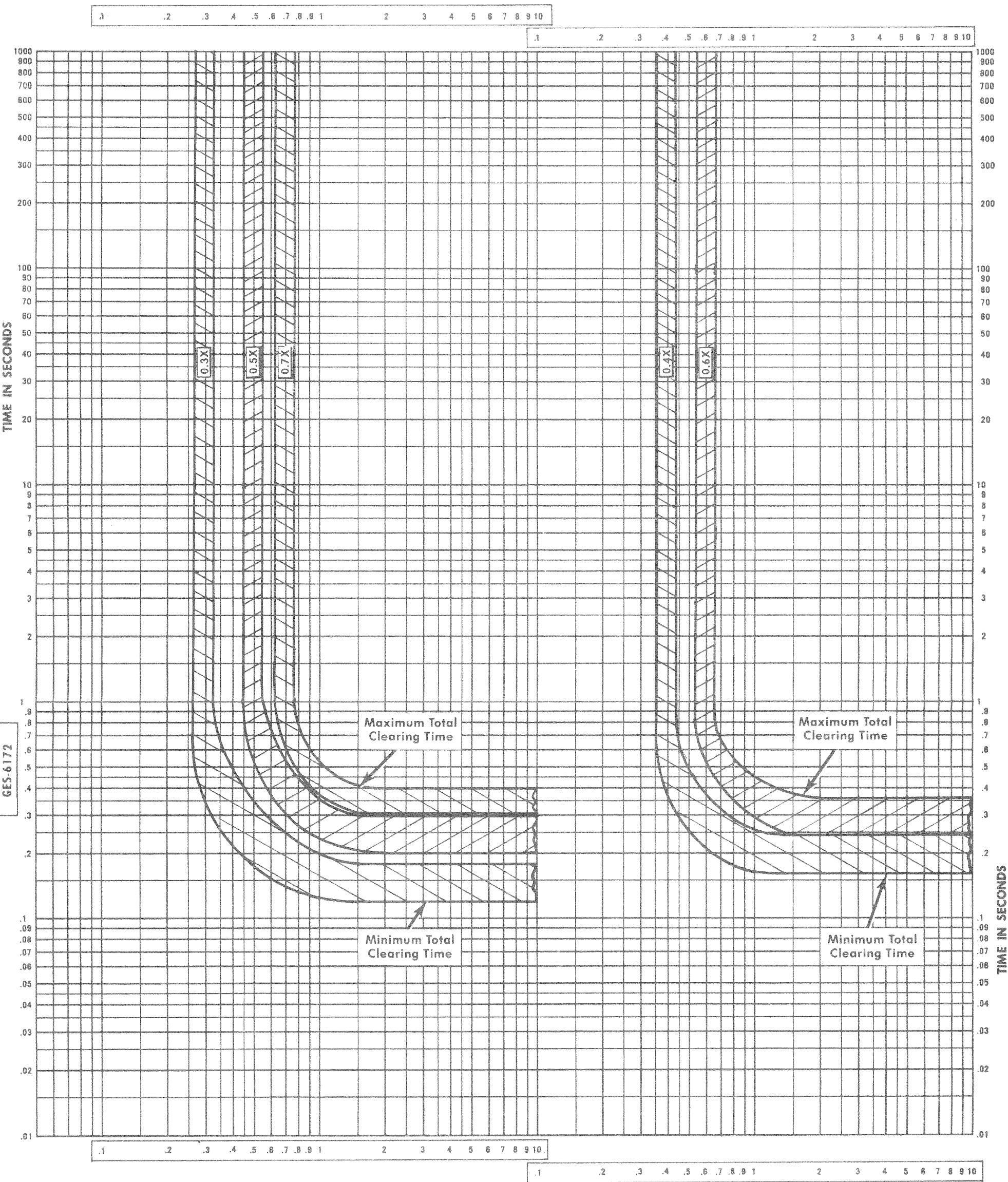

MULTIPLES OF SENSOR AMPERE RATING

<p><b>GENERAL ELECTRIC</b></p>	<p>INSULATED-CASE CIRCUIT BREAKER  <b>POWER BREAK<sup>®</sup></b>  <b>With SelecTrip<sup>™</sup></b></p>	<p><b>GES-6172</b></p>
<p><b>Sensor Rating (Amperes)</b> 800, 1000, 1200, 1600 amperes</p> <p><b>Voltage Rating</b> 600 volts ac</p> <p><b>Frequency Rating</b> 50/60 Hertz</p>	<p>Types TPR, THR, TPRR, THRR</p> <p><b>Ground Fault Pickup Settings and Delay Time-current Curves</b></p> <p><small>(Curves apply at 50/60 Hertz and from -20C to +55C breaker ambient)</small></p>	<p><b>Adjustments</b></p> <p>Ground Fault Unit: Pick-up current settings are 0.3x, 0.4x, 0.5x, 0.6x, and 0.7x of breaker sensor ampere rating. Time-delay bands vary with pick-up current setting as shown above.</p>

11-77-5M1

GENERAL ELECTRIC CO., CIRCUIT PROTECTIVE DEVICES DEPT., PLAINVILLE, CONN. 06062