


MULTIPLES OF AMPERE SETTING (CONTINUOUS)

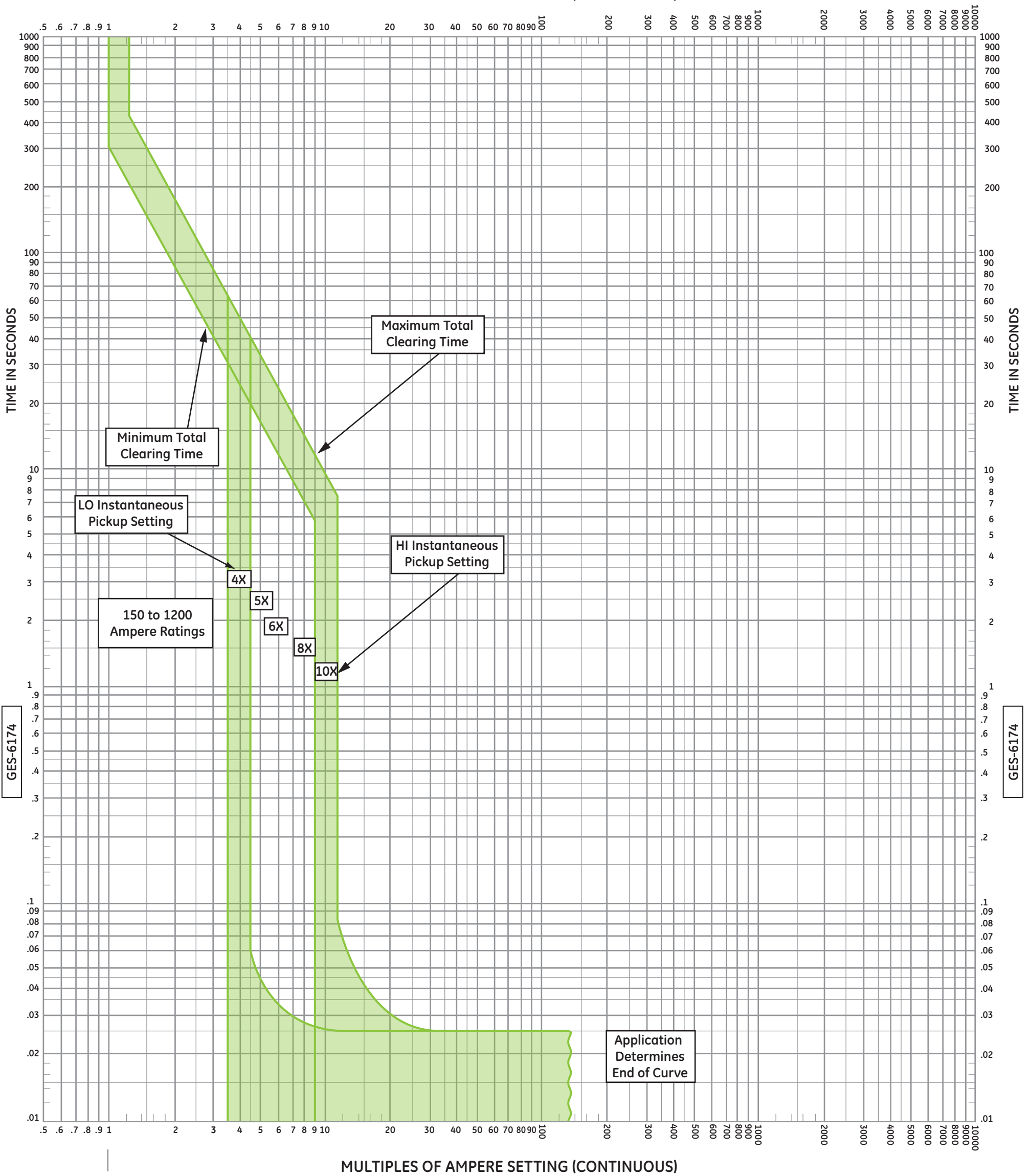

GE Consumer & Industrial -  
Electrical Distribution

**Sensor Rating (Amperes)**

150, 200, 300, 400, 500, 600, 800, 1000,  
1200 Amperes

**Voltage Rating**

600 Vac

**Frequency Rating**

50/60 Hertz

**Molded Case Circuit Breaker  
SelectTrip™**

Types TJR, THJR, TKR, THKR

**Long-time and Instantaneous  
Time-current Curves**

Curves apply at 50/60 Hertz and  
from -20°C to +55°C breaker ambient.

**GES-6174**

**Adjustments**

Long-time Delay Unit: Continuous current settings are  
50, 60, 70, 80, 90 and 100% of sensor rating.

Instantaneous Unit: Pick-up current settings are 4X, 5X,  
6X, 8X and 10X multiples of Long-time unit settings for  
ampere ratings of 150 to 1200.