


MULTIPLES OF CURRENT PICKUP SETTING

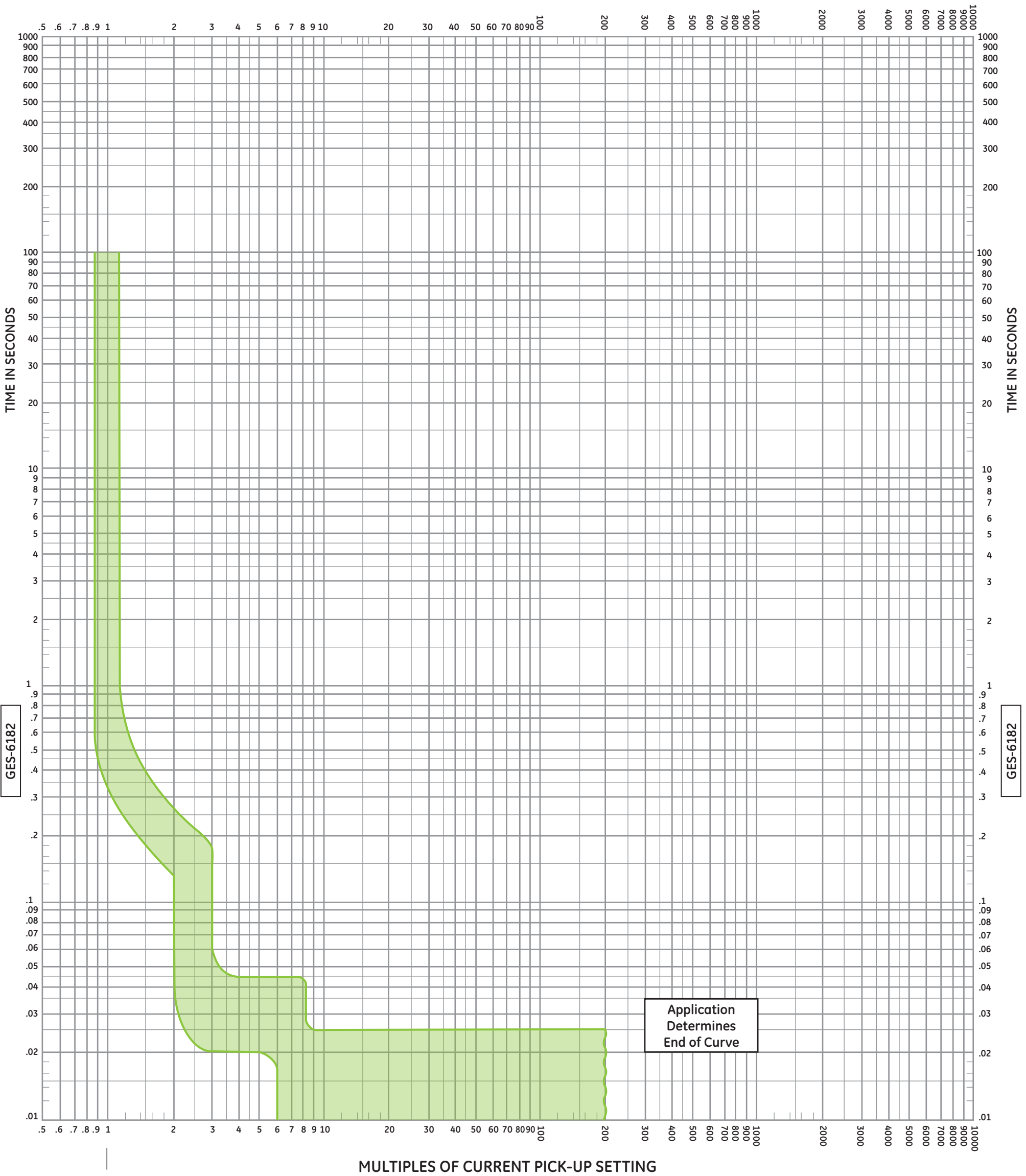

GE Consumer & Industrial -  
Electrical Distribution

**Current Pick-up Settings  
(Amperes)**

- 0.1, 0.2, 0.3, 0.4, 0.5, 0.6
- 1, 2, 3, 4, 5, 6
- 2, 4, 6, 8, 10, 12
- 5, 10, 15, 20, 25, 30

**Control Voltage**

120 Vac

**Molded Case Circuit Breaker  
GROUND-BREAK® TYPE MC**

Type TMCGR1S

Equipment and Personnel Ground Fault  
Protective Relay Time-current Curves

Curves apply at 50/60 Hertz  
and from -20°C to 60°C ambient

**GES-6182**

**Adjustments**

Ground current pick-up setting made by  
changing tap setting on the Type TMCGRS  
current transformers.