


MULTIPLES OF CURRENT PICKUP SETTING

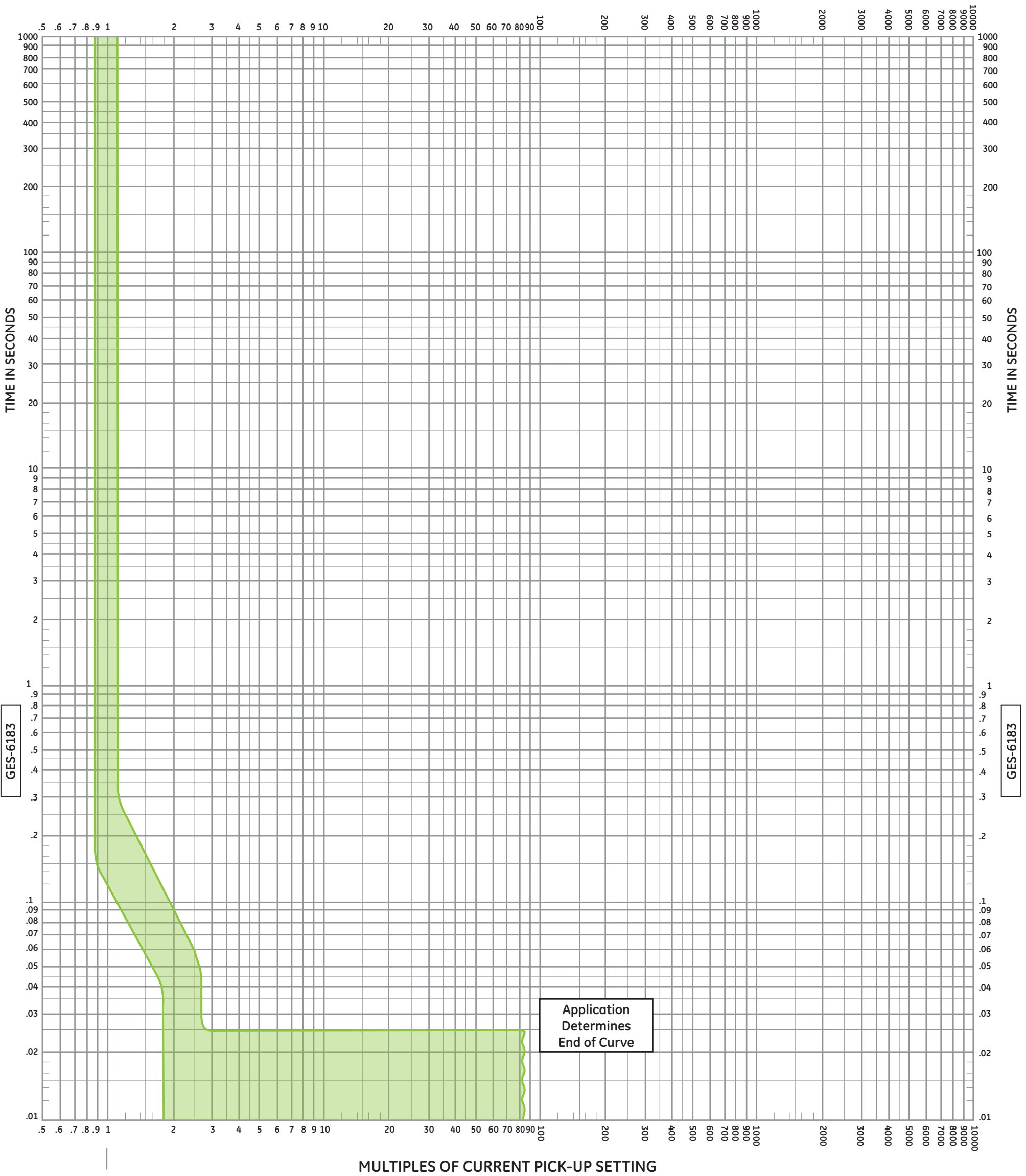

GE Consumer & Industrial -
Electrical Distribution

**Current Pick-up Settings
(Amperes)**

0.5, 1.0, 1.5, 2.0, 2.5, 3.0

1, 2, 3, 4, 5, 6

2, 4, 6, 8, 10, 12

5, 10, 15, 20, 25, 30

Control Voltage

120 Vac

Frequency Rating

60 Hertz

**Molded Case Circuit Breaker
GROUND-BREAK® TYPE MC**

Type TMCGR

Equipment and Personnel Ground Fault
Protective Relay Time-current Curves

Curves apply at 50/60 Hertz
and from -20°C to 60°C ambient

GES-6183

Adjustments

Ground current pick-up setting made by
changing tap setting on the Type TMCGRS
current transformers.