


MULTIPLES OF SENSOR AMPERE RATING

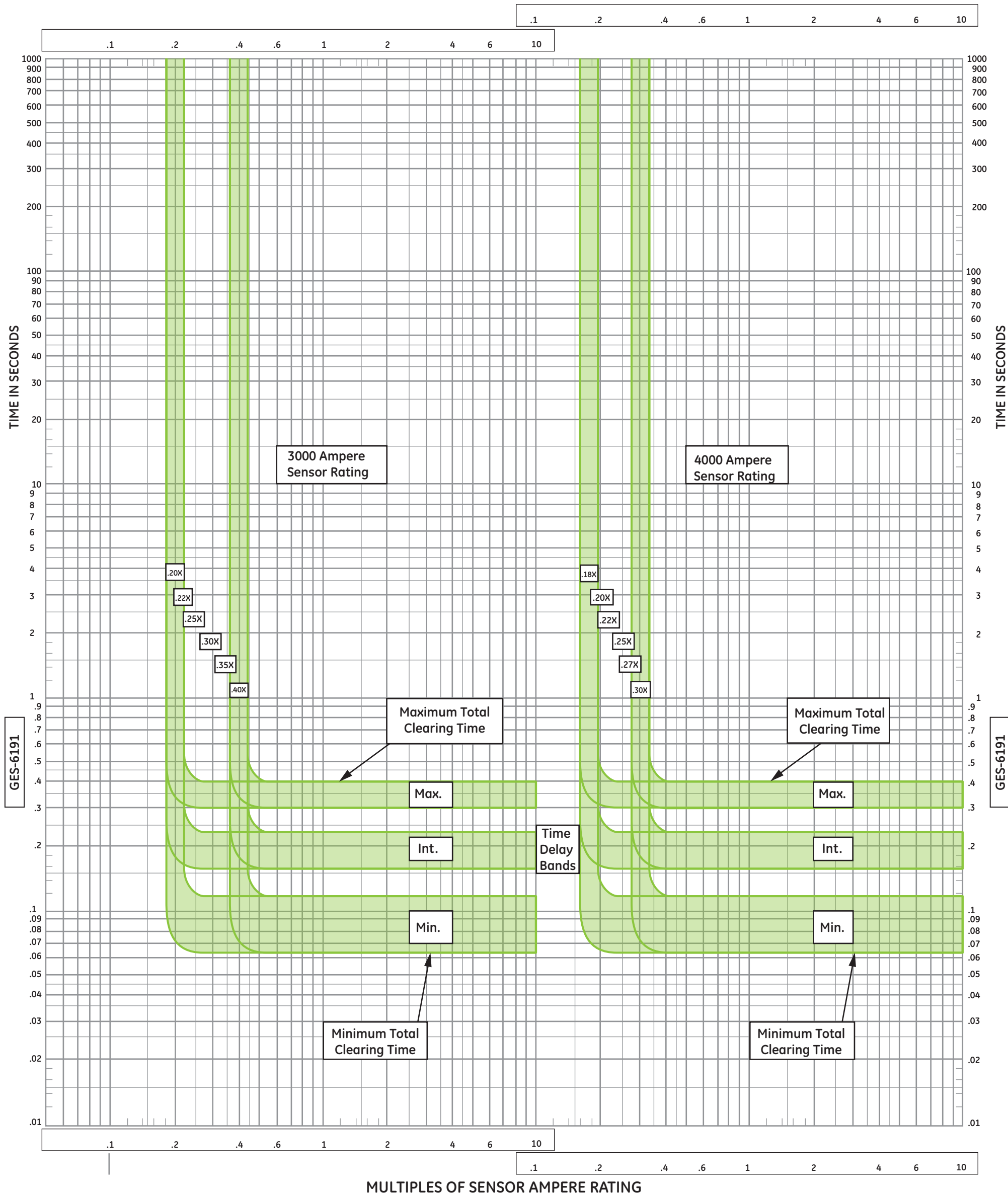

GE Consumer & Industrial -  
Electrical Distribution

**Sensor Rating**  
3000, 4000 Amperes

**Voltage Rating**  
600 Vac

**Frequency Rating**  
50/60 Hertz

**Insulated-Case Circuit Breaker  
POWER BREAK® with  
Solid State VersaTrip® MOD2**

Types TPSS, THSS  
Ground Fault Pickup Settings  
and Delay Time-current Curves

Curves apply at 50/60 Hertz and  
from -20°C to +55°C breaker ambient.

**GES-6191**

**Adjustments**

Ground Fault Unit: Pick-up current settings are 0.20X, 0.22X, 0.25X, 0.30X, 0.35X and 0.40X for 3000A sensor rating, and 0.18X, 0.20X, 0.22X, 0.25X, 0.27X and 0.30X for 4000A sensor rating. Time-delay bands are maximum, intermediate and minimum.