


MULTIPLES OF CURRENT RATING

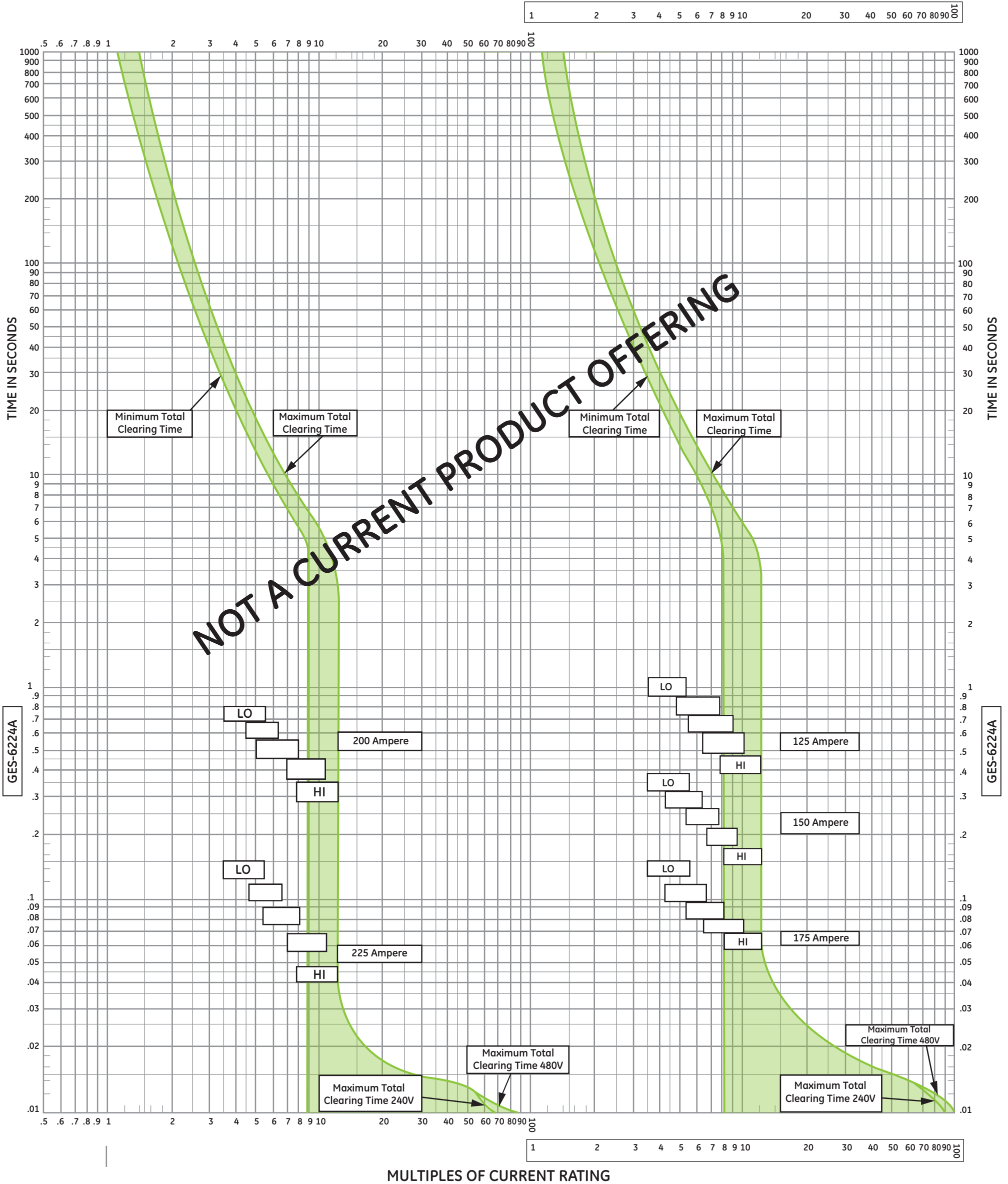

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

125, 150, 175, 200 and 225 Amperes

Voltage Ratings

240 Volts, 480 Volts

Frequency Rating

50/60 Hertz

Molded Case Circuit Breakers

Type TLB2

Ambient Compensated

Long-time Delay and Instantaneous
Time-current Curves

Curves show ambient-compensated circuit breaker
in open air, 10°C to 50°C ambient, wired with
conductors of corresponding rating, no prior load.


GES-6224A

Adjustments

Long-time delay thermal trip: not adjustable.

Instantaneous magnetic trip: continuously
adjustable, factory-set on Hi.

Blocks show trip range at marked points on
instantaneous dials.

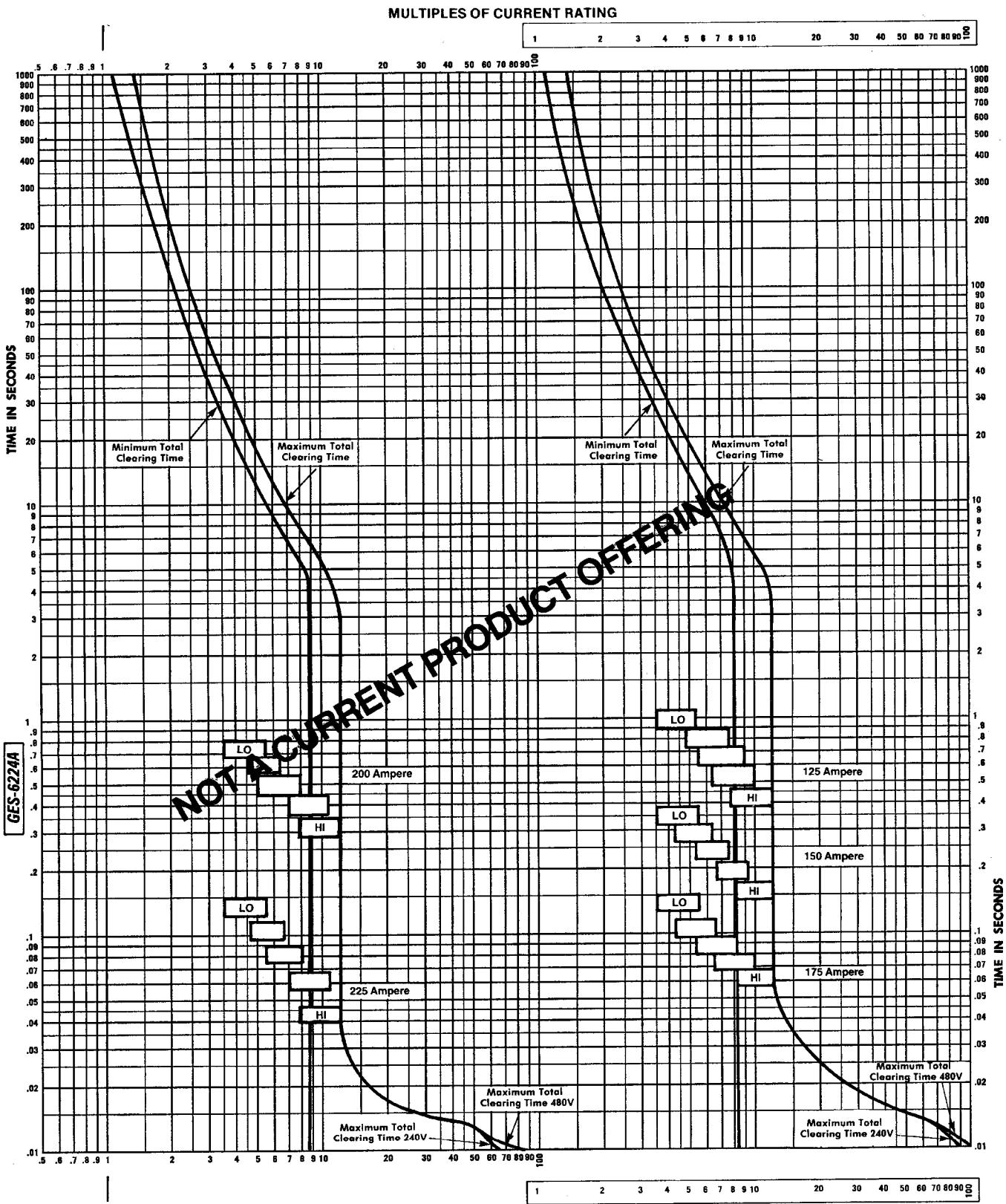

GE
GE Electrical Distribution & Control
 General Electric Company
 Plainville, CT 06062

Current Ratings
 125, 150, 175, 200 and 225 Amperes

Voltage Ratings
 240 Volts, 480 Volts

Frequency Rating
 50/60 Hertz

**Molded Case Circuit Breakers
 Type TLB2**

**Ambient Compensated
 Long-time Delay and Instantaneous
 Time-current Curves**

Curves show ambient-compensated circuit breaker in open air, 10-50° C ambient, wired with conductors of corresponding rating, no prior load.

GES-6224A

Adjustments

Long-time delay thermal trip: not adjustable.
 Instantaneous magnetic trip: continuously adjustable, factory-set on Hi.
 Blocks show trip range at marked points on instantaneous dials.