


Temp. 25 40 50

Shift index for long-time delay only.

MULTIPLES OF CURRENT RATING

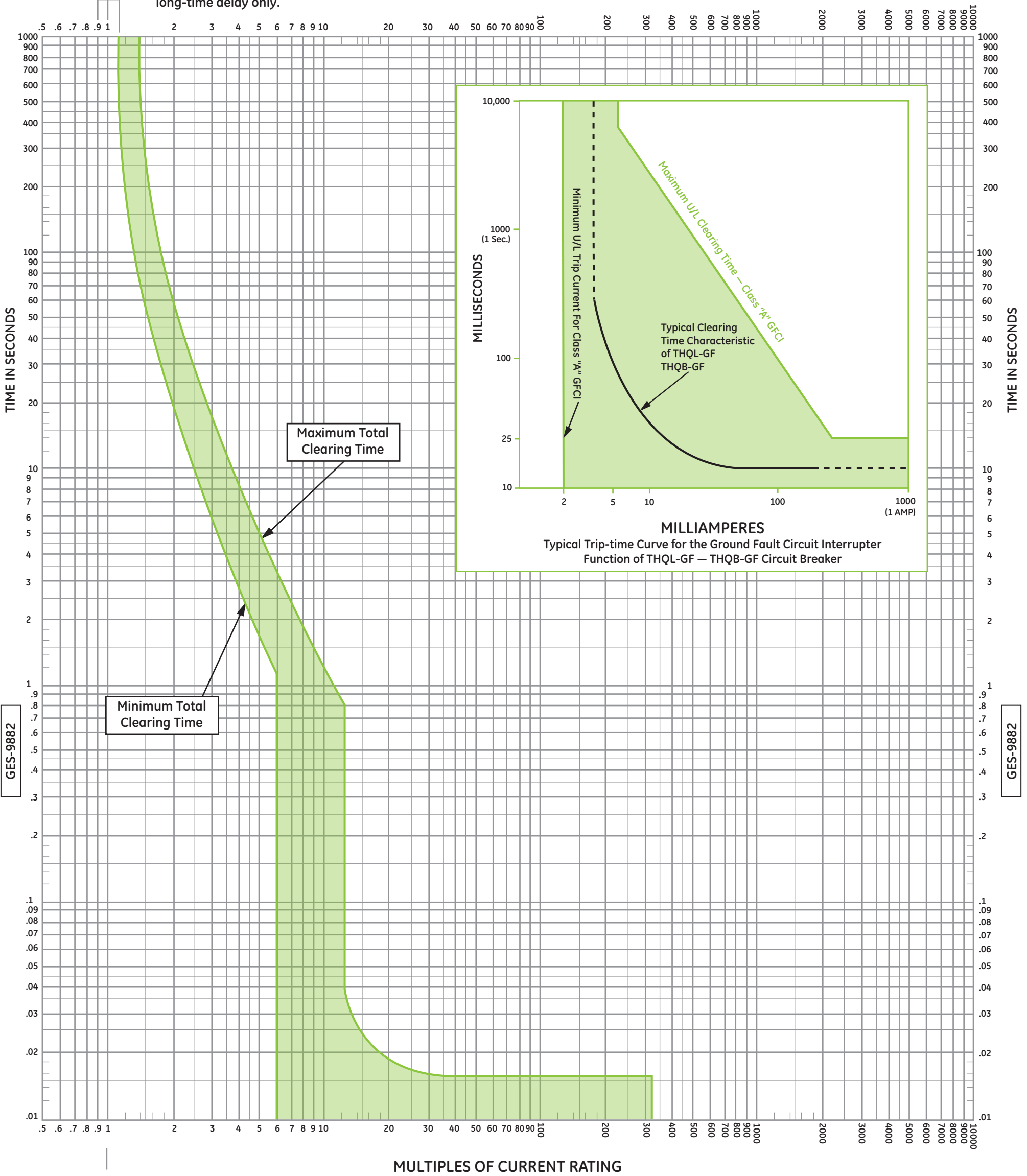

GE Consumer & Industrial - Electrical Distribution

Current Ratings

20 Amperes
1-pole and 2-pole

Voltage Rating

120/240 Vac

Frequency Ratings

60 Hertz

Molded Case Circuit Breaker with Ground Fault Circuit Interrupter Q Line

Types THQL-GF — THQB-GF
(Breakers Manufactured After MAY 2, 1994)
Enclosure Compensated
Long-time Delay and Instantaneous
Time-current Curves

Curves show circuit breaker in open air, 40°C ambient, wired with conductors of corresponding rating, no prior load. For all other ambients, use rating shift index at top of sheet.

GES-9882

No Adjustments Available