


Shift index for long-time delay only.

MULTIPLES OF CURRENT RATING

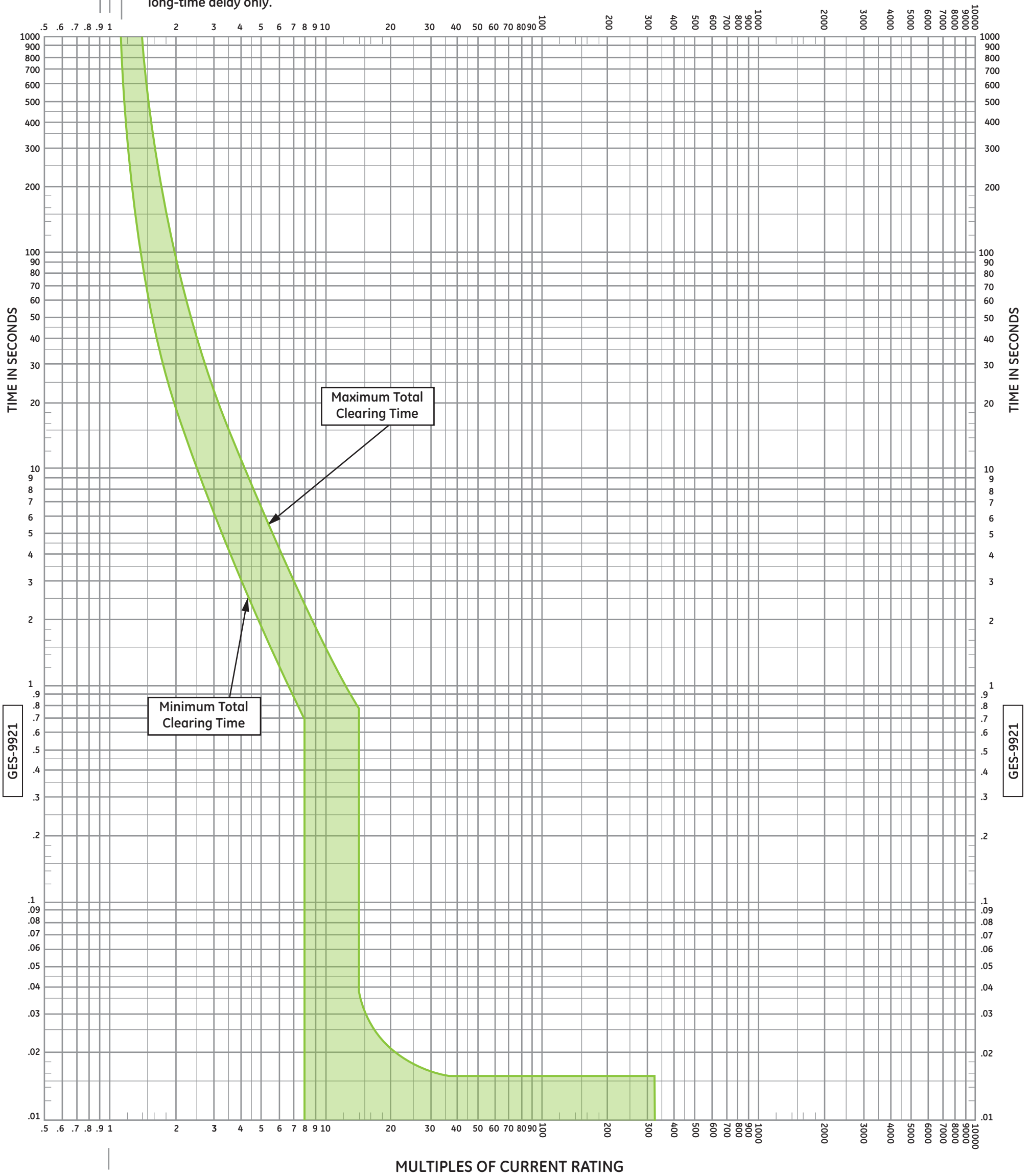

GE Consumer & Industrial - Electrical Distribution

Current Ratings

15, 20, 25, 30, 35, 40, 45 and 50 Amperes

Voltage Ratings

120/240 Vac

Frequency Rating

60 Hertz

Molded Case Circuit Breakers Q Line

Type TQP (1 and 2 Pole)

Long-time Delay and Instantaneous Time-current Curves

Curves show circuit breaker in open air, 40°C ambient, wired with conductors of corresponding rating, no prior load. For all other ambients, use rating shift index at top sheet.

GES-9921

Adjustments

Long-time delay thermal trip: not adjustable.

Instantaneous magnetic trip: not adjustable.