


Temp. 25C 40C 50C



Shift index for long-time delay only.

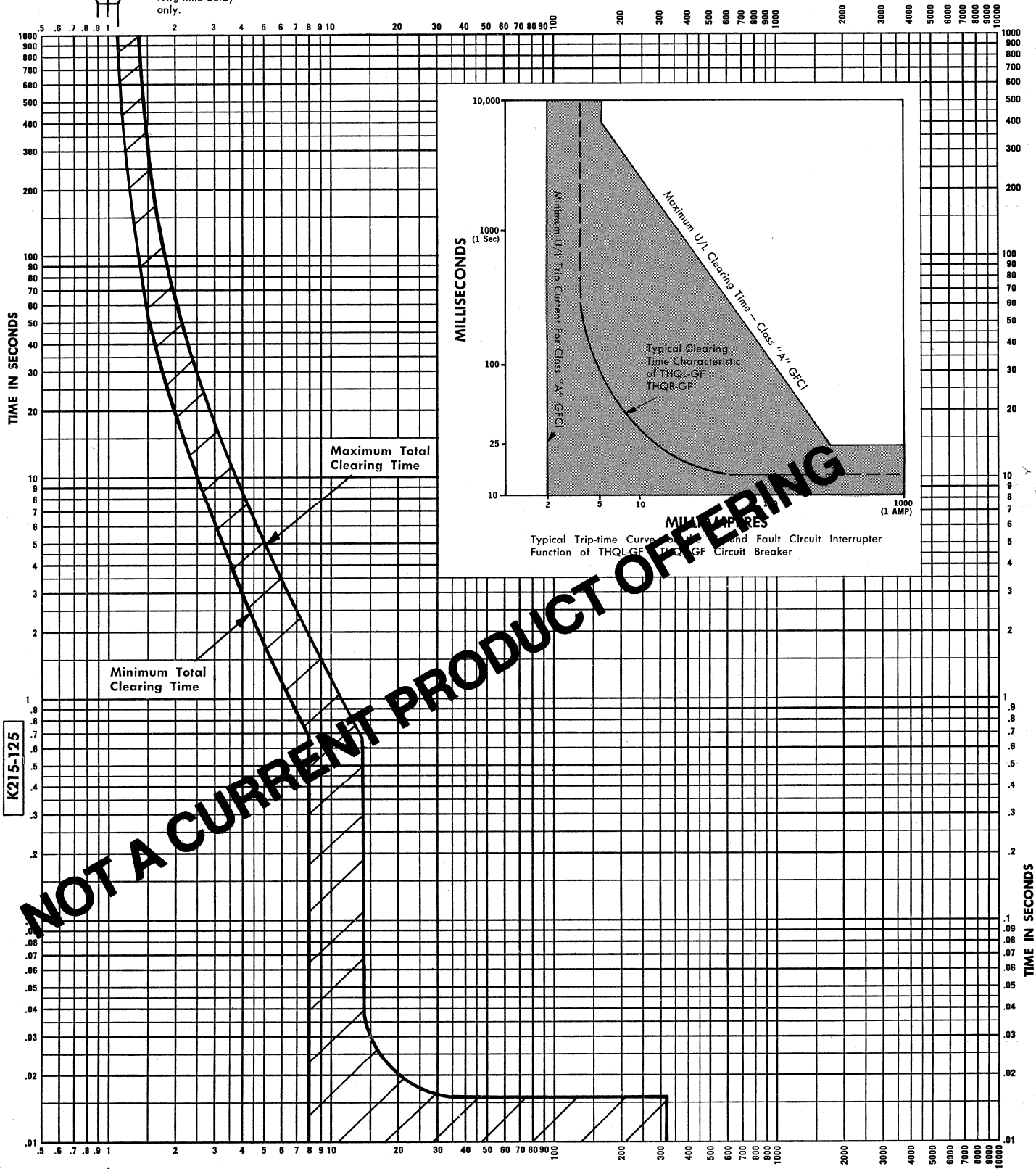

K215-125

NOT A CURRENT PRODUCT OFFERING

MULTIPLES OF CURRENT RATING

GENERAL ELECTRIC

MOLDED-CASE CIRCUIT BREAKER WITH GROUND FAULT CIRCUIT INTERRUPTER

K215-125

Current Ratings
15, 20, 25, 30 Amperes
1 Pole
Voltage Rating
120 Volts A-c
Frequency Rating
60 Hertz

Q LINE
ENCLOSURE COMPENSATED
Type THQL-GF - THQB-GF

Long-time Delay and Instantaneous Time-current Curves

(Curves show circuit breaker in open air, 40°C ambient, wired with conductors of corresponding rating, no prior load. For all other ambients use rating shift index at top of sheet.)

No Adjustments Available