


Temp. 0 10-50 60C

Shift index for long-time delay only.

MULTIPLES OF CIRCUIT BREAKER CURRENT RATING

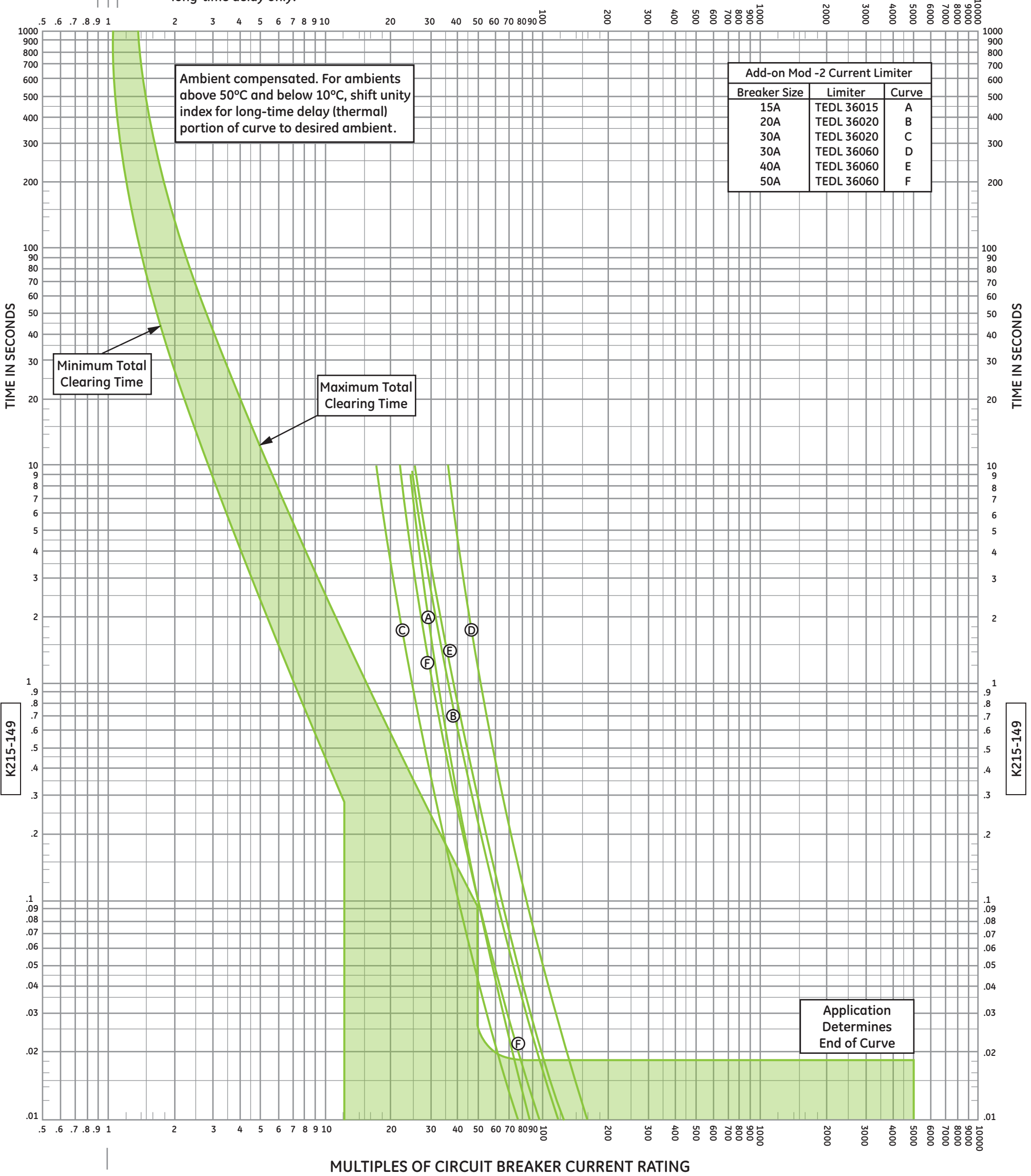

GE Consumer & Industrial - Electrical Distribution

Current Ratings

15, 20, 30, 40 and 50 Amperes

Voltage Ratings

2 and 3 pole - 600 Vac

Frequency Rating

60 Hertz

Molded Case Circuit Breaker E 150 LINE

Types TED, THED, 15-50 Amperes
Ambient Compensated
Long-time Delay and Instantaneous
Time-current Curves

Curves show ambient-compensated circuit breaker in open air, 10°C to 50°C ambient, wired with conductors of corresponding rating, no prior load. For all other ambients, use rating shift index at top of sheet.

K215-149

Adjustments

Long-time delay thermal trip: not adjustable.
Instantaneous magnetic trip: not adjustable.

NOTE: Limiters can only be applied to AC breakers.