


CURRENT IN MULTIPLES OF RATING PLUG AMPERES

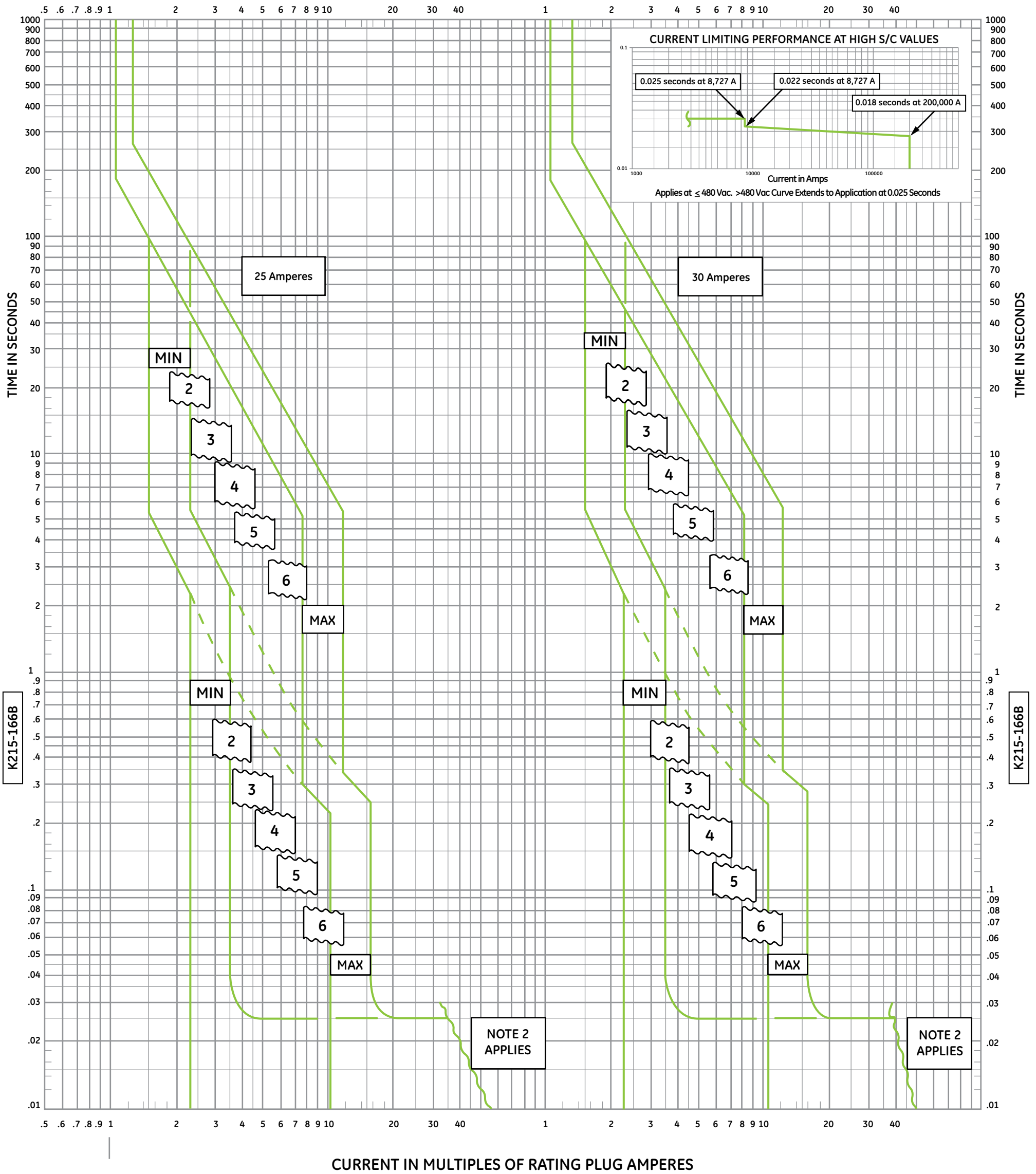

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

Frame Amperes	Rating Plug Amperes
30	25, 30

Voltage Ratings

2-pole—480 Vac max.
3-pole—600 Vac max.

**Molded Case Circuit Breakers
Type SE with Spectra RMS®
Solid-state Trip**

Long-time Delay and Instantaneous
with Tracking Short-time Delay
Time-current Curves

Curves apply at 50 to 400 Hertz
and from -20°C to 70°C breaker ambient

K215-166B

Adjustments

Long-time delay; not adjustable.
Instantaneous pick-up settings in multiples of rating plug
rating: MIN, 2, 3, 4, 5, 6, MAX

Note 1: Operation above 60 Hertz and 50°C play require
thermal and interrupting derating of the circuit breaker.
Refer to Selection and Application manual.

Note 2: Current limiting range, please refer to inset curve.