


CURRENT IN MULTIPLES OF RATING PLUG AMPERES

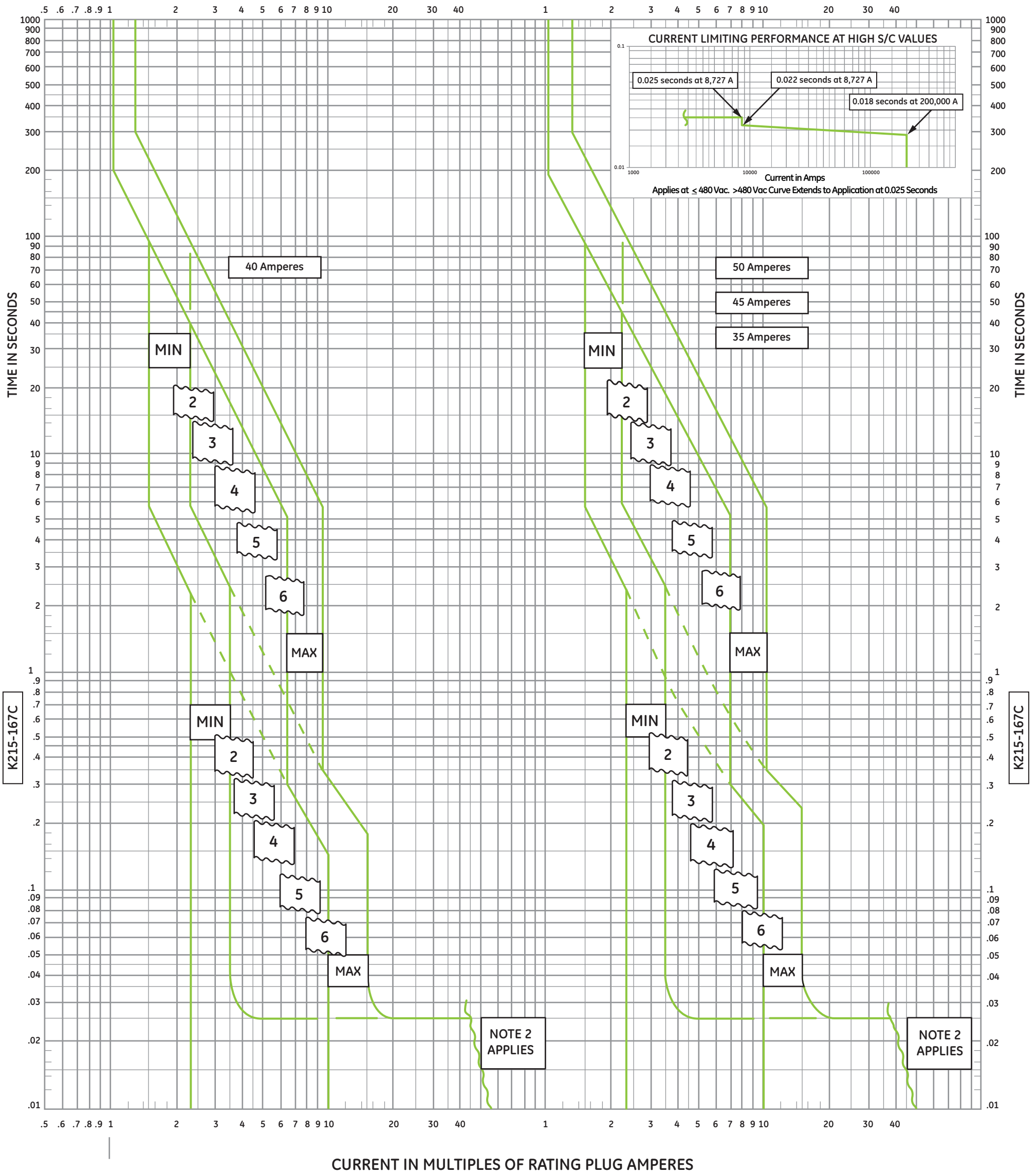

GE Industrial Solutions

Current Ratings

Frame Amperes	Rating Plug Amperes
60	35, 40, 45, 50

Voltage Ratings

2-pole—480 Vac max.  
3-pole—600 Vac max.

Molded Case Circuit Breakers  
Type SE with Spectra RMS®  
Solid-state Trip

Long-time Delay and Instantaneous with Tracking Short-time Delay  
Time-current Curves

Curves apply at 50 to 400 Hertz and from -20°C to 70°C breaker ambient

K215-167C

Adjustments

Long-time delay; not adjustable.  
Instantaneous pick-up settings in multiples of rating plug rating: MIN, 2, 3, 4, 5, 6, MAX

**Note 1:** Operation above 60 Hertz and 50°C play require thermal and interrupting derating of the circuit breaker. Refer to Selection and Application manual.

**Note 2:** Current limiting range, please refer to inset curve.