


CURRENT IN MULTIPLES OF RATING PLUG AMPERES

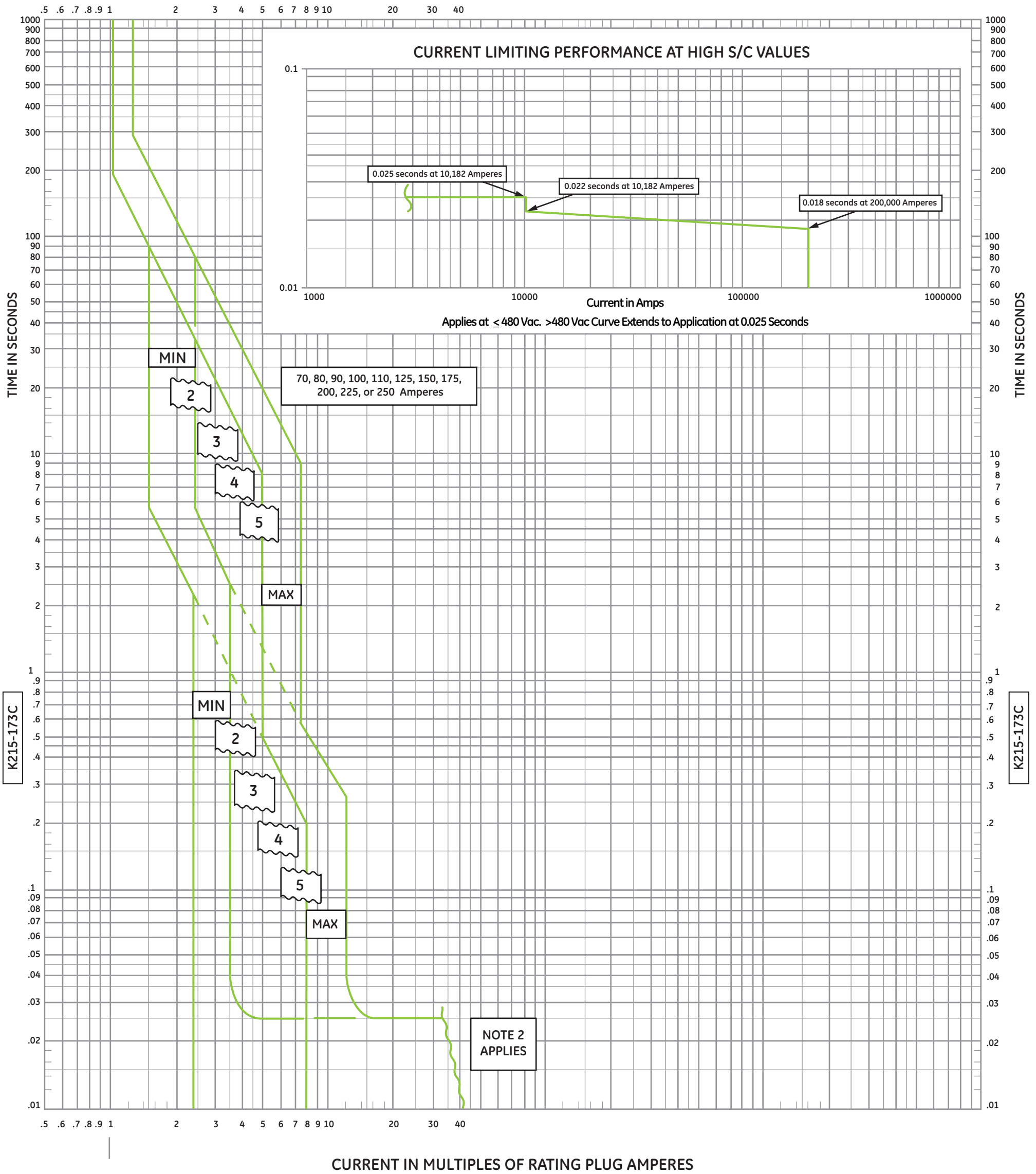

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

Frame Amperes	Rating Plug Amperes
250	70, 80 90, 100, 110, 125, 150, 175, 200, 225, 250

Voltage Ratings

2-pole—480 Vac max.
3-pole—600 Vac max.

**Molded Case Circuit Breakers
Type SF with Spectra RMS®
Solid-state Trip**

Long-time Delay and Instantaneous
with Tracking Short-time Delay
Time-current Curves

Curves apply at 50 to 400 Hertz
and from -20°C to 70°C breaker ambient

K215-173C

Adjustments

Long-time delay; not adjustable.

Instantaneous pick-up settings in multiples of rating plug rating: MIN, 2, 3, 4, 5, MAX

Note 1: Operation above 60 Hertz and 50°C play require thermal and interrupting derating of the circuit breaker. Refer to Selection and Application manual.

Note 2: Current limiting range, please refer to inset curve.