


CURRENT IN MULTIPLES OF RATING PLUG AMPERES

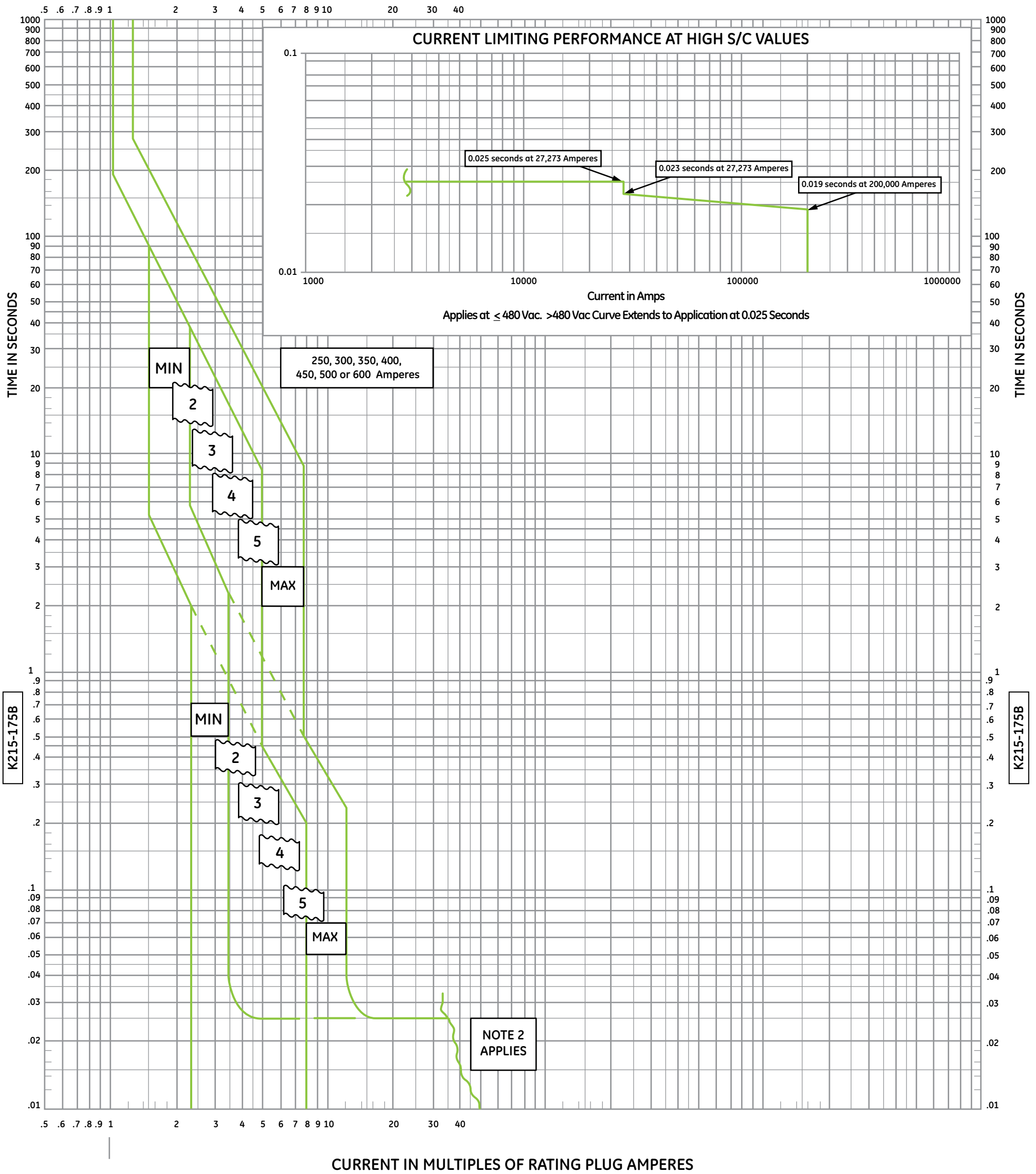

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

Frame Amperes	Rating Plug Amperes
600	250, 300, 350, 400, 450, 500, 600

Voltage Ratings

240, 480, 600 Vac

**Molded Case Circuit Breakers
Type SG with Spectra RMS®
Solid-state Trip**

Long-time Delay and Instantaneous
with Tracking Short-time Delay
Time-current Curves

Curves apply at 50 to 400 Hertz
and from -20°C to 70°C breaker ambient

K215-175B

Adjustments

Long-time delay; not adjustable.

Instantaneous pick-up settings in multiples of rating plug rating: MIN, 2, 3, 4, 5, MAX

Note 1: Operation above 60 Hertz and 50°C play require thermal and interrupting derating of the circuit breaker. Refer to Selection and Application manual.

Note 2: Current limiting range, please refer to inset curve.