


CURRENT IN MULTIPLES OF RATING PLUG AMPERES

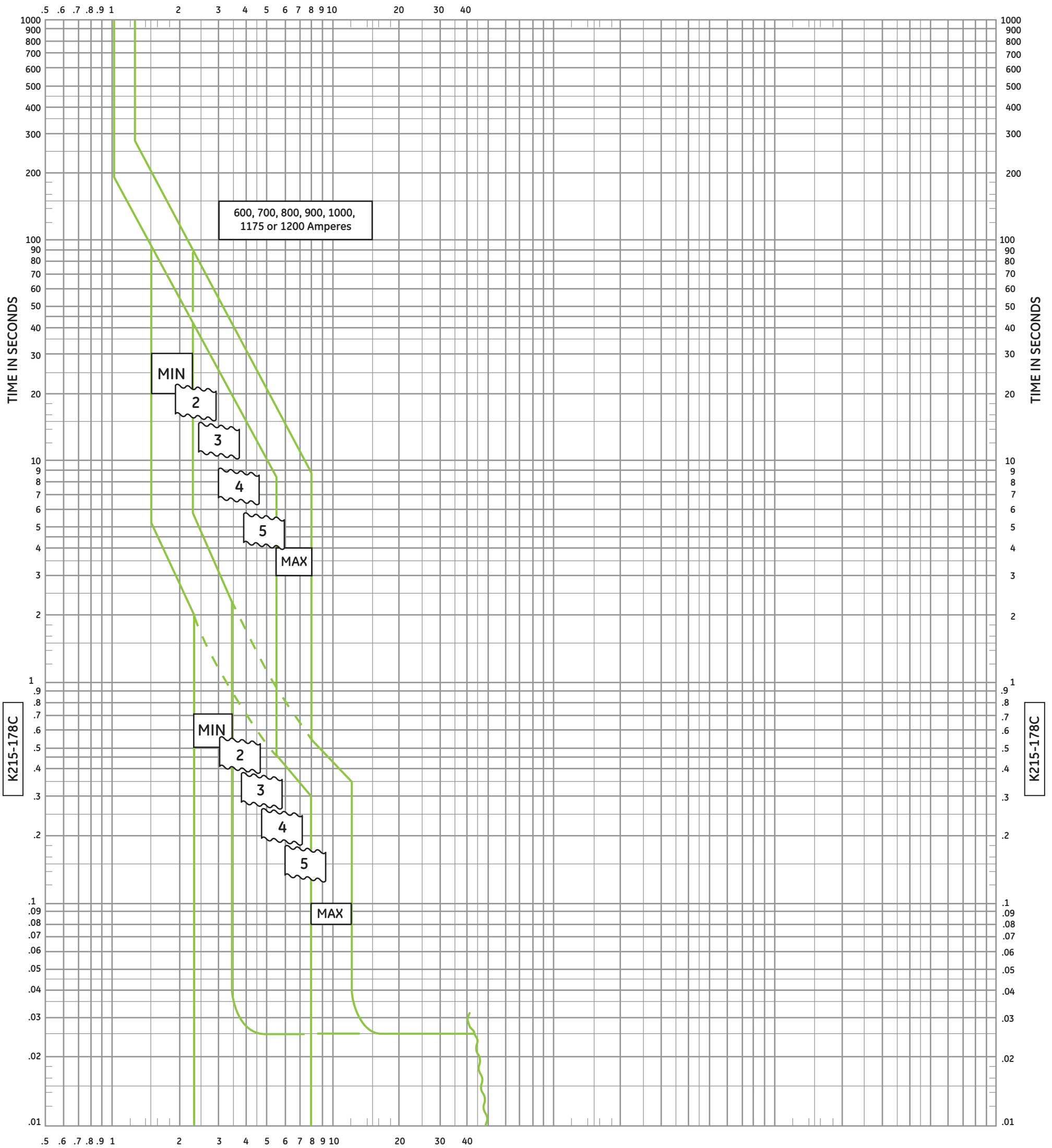

CURRENT IN MULTIPLES OF RATING PLUG AMPERES



GE Industrial Solutions

Current Ratings

Frame Amperes	Rating Plug Amperes
1200	600, 700, 800, 900, 1000, 1175, 1200

Voltage Ratings

240, 480, 600 Vac

Molded Case Circuit Breakers
Type SK with Spectra RMS®
Solid-state Trip

Long-time Delay and Instantaneous with Tracking Short-time Delay
Time-current Curves

Curves apply at 50 to 400 Hertz and from -20°C to 70°C breaker ambient

K215-178C

Adjustments

Instantaneous pick-up settings in multiples of rating plug rating: MIN, 2, 3, 4, 5, MAX

Note 1: Operation above 60 Hertz and 50°C play require thermal and interrupting derating of the circuit breaker. Refer to Selection and Application manual.