


CURRENT IN MULTIPLES OF RATING PLUG AMPERES

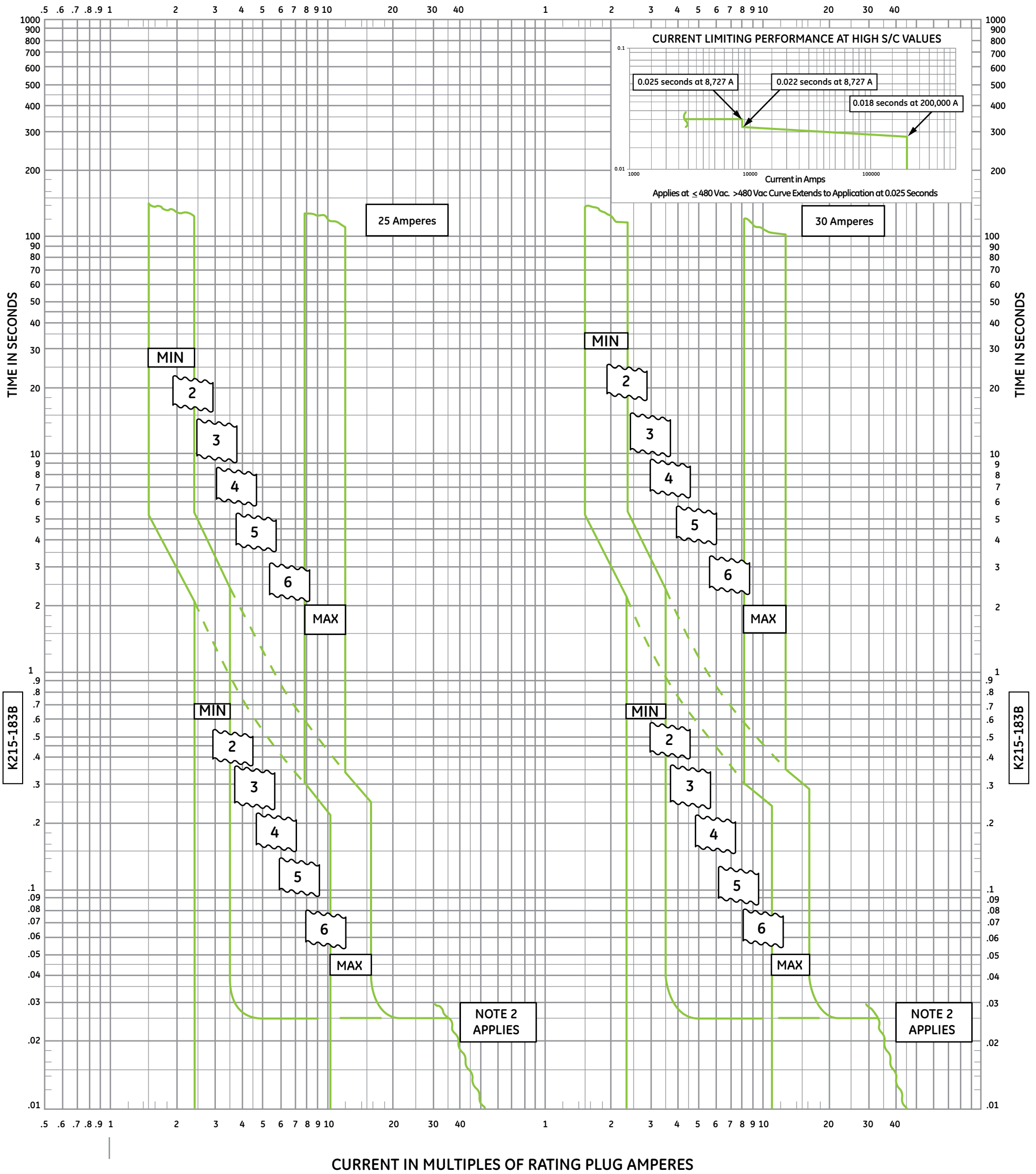

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

Frame Amperes	Rating Plug Amperes
30	25, 30

Voltage Ratings

2 Pole — 480 Vac max.
3 Pole — 600 Vac max.

**MAG-BREAK® Motor Circuit Protector
Type SE with Spectra RMS®
Solid-state Trip**

Instantaneous
with Tracking Short-time Delay
Time-current Curves

Curves apply at 50 to 400 Hertz
and from -20°C to 70°C breaker ambient

K215-183B

Adjustments

Long-time delay; not adjustable.
Instantaneous pick-up settings in multiples of rating plug rating: MIN, 2, 3, 4, 5, 6, MAX

Note 1: Operation above 60 Hertz and 50°C play require thermal and interrupting derating of the circuit breaker. Refer to Selection and Application manual.

Note 2: Current limiting range, please refer to inset curve.