


CURRENT IN MULTIPLES OF RATING PLUG AMPERES

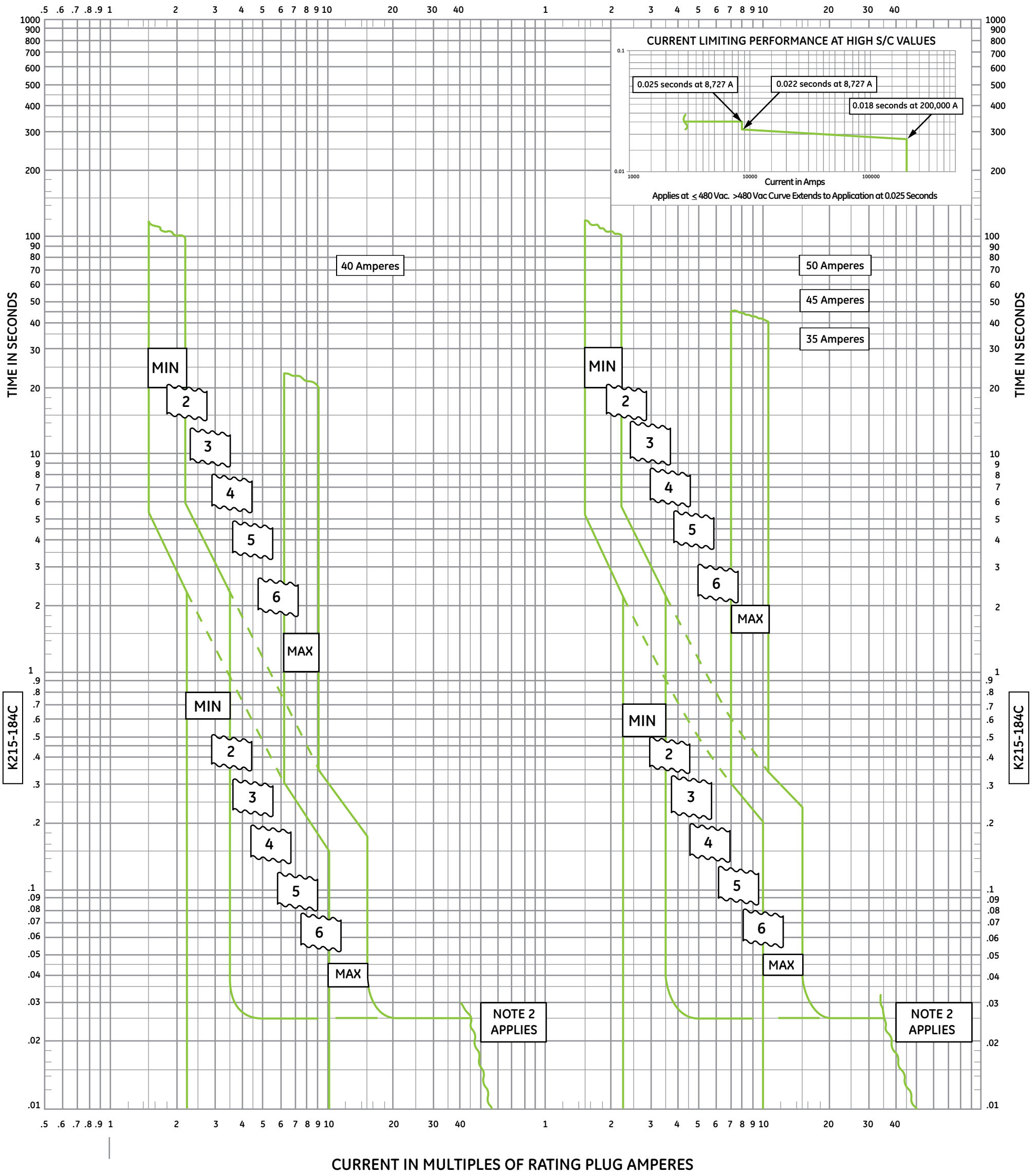

CURRENT IN MULTIPLES OF RATING PLUG AMPERES



GE Industrial Solutions

Current Ratings

Frame Amperes	Rating Plug Amperes
60	35, 40, 45, 50

Voltage Ratings

2 Pole — 480 Vac max.
3 Pole — 600 Vac max.

MAG-BREAK® Motor Circuit Protector
Type SE with Spectra RMS®
Solid-state Trip

Instantaneous with Tracking Short-time Delay
Time-current Curves

Curves apply at 50 to 400 Hertz and from -20°C to 70°C breaker ambient

K215-184C

Adjustments

Long-time delay; not adjustable.
Instantaneous pick-up settings in multiples of rating plug rating: MIN, 2, 3, 4, 5, 6, MAX.

Note 1: Operation above 60 Hertz and 50°C play require thermal and interrupting derating of the circuit breaker. Refer to Selection and Application manual.

Note 2: Current limiting range, please refer to inset curve.