


CURRENT IN MULTIPLES OF RATING PLUG AMPERES

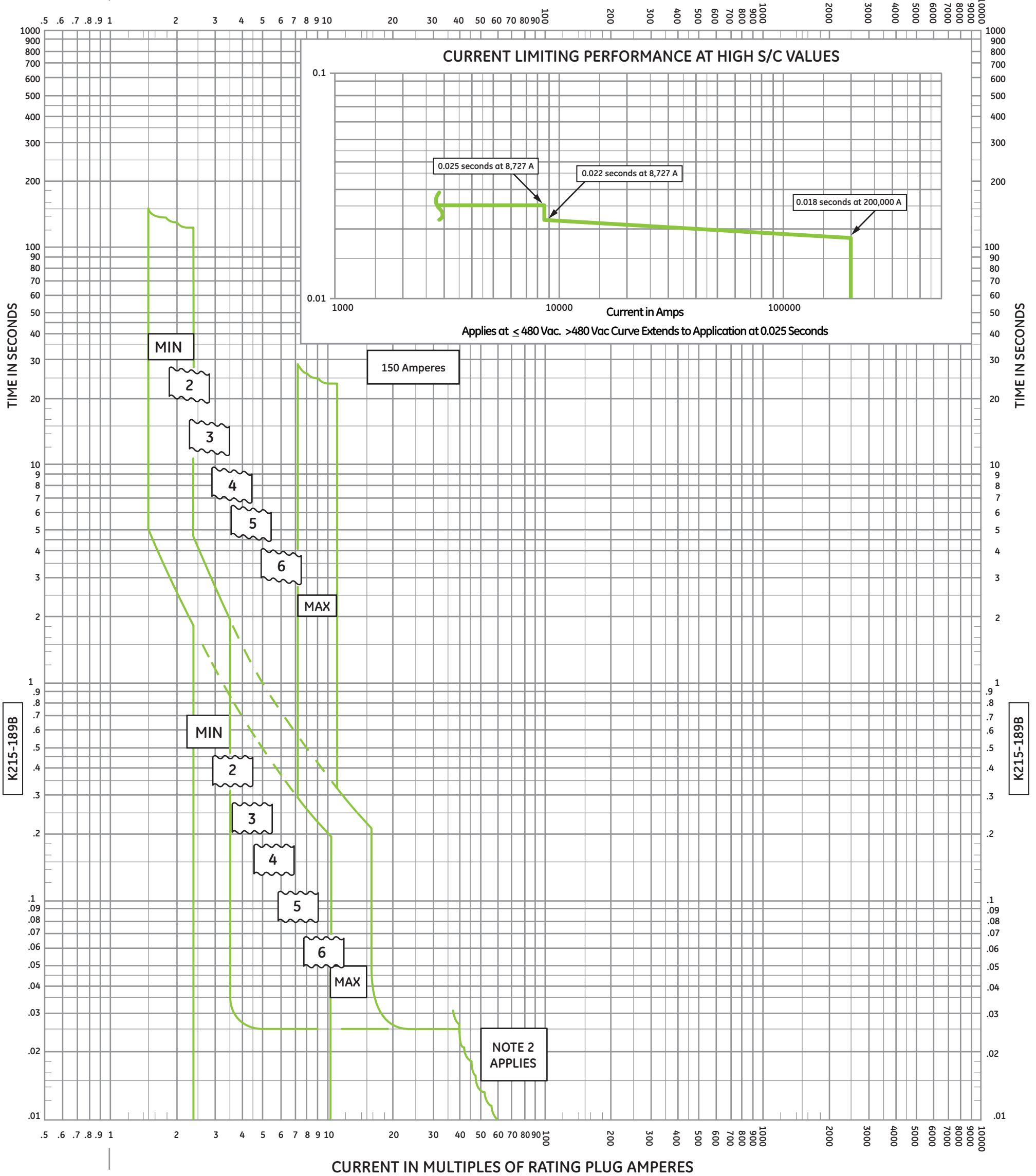

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

Frame Amperes	150
Rating Plug Amperes	150

Voltage Ratings

2 Pole	480 Vac max.
3 Pole	600 Vac max.

**MAG-BREAK™ Motor Circuit Protector
Type SE with Spectra RMS™
Solid-state Trip**

Instantaneous
with Tracking Short-time Delay
Time-current Curves

Curves apply at 50 to 400 Hertz
and from -20°C to 70°C breaker ambient

K215-189B

Adjustments

Instantaneous pick-up settings in multiples
of plug rating: MIN, 2,3,4,5,6 MAX

Note 1: Operation above 60 Hertz and 50° C play require
thermal and interrupting derating of the circuit breaker.
Refer to Selection and Application manual.

Note 2: Current limiting range, please refer to inset curve.