


CURRENT IN MULTIPLES OF RATING PLUG AMPERES

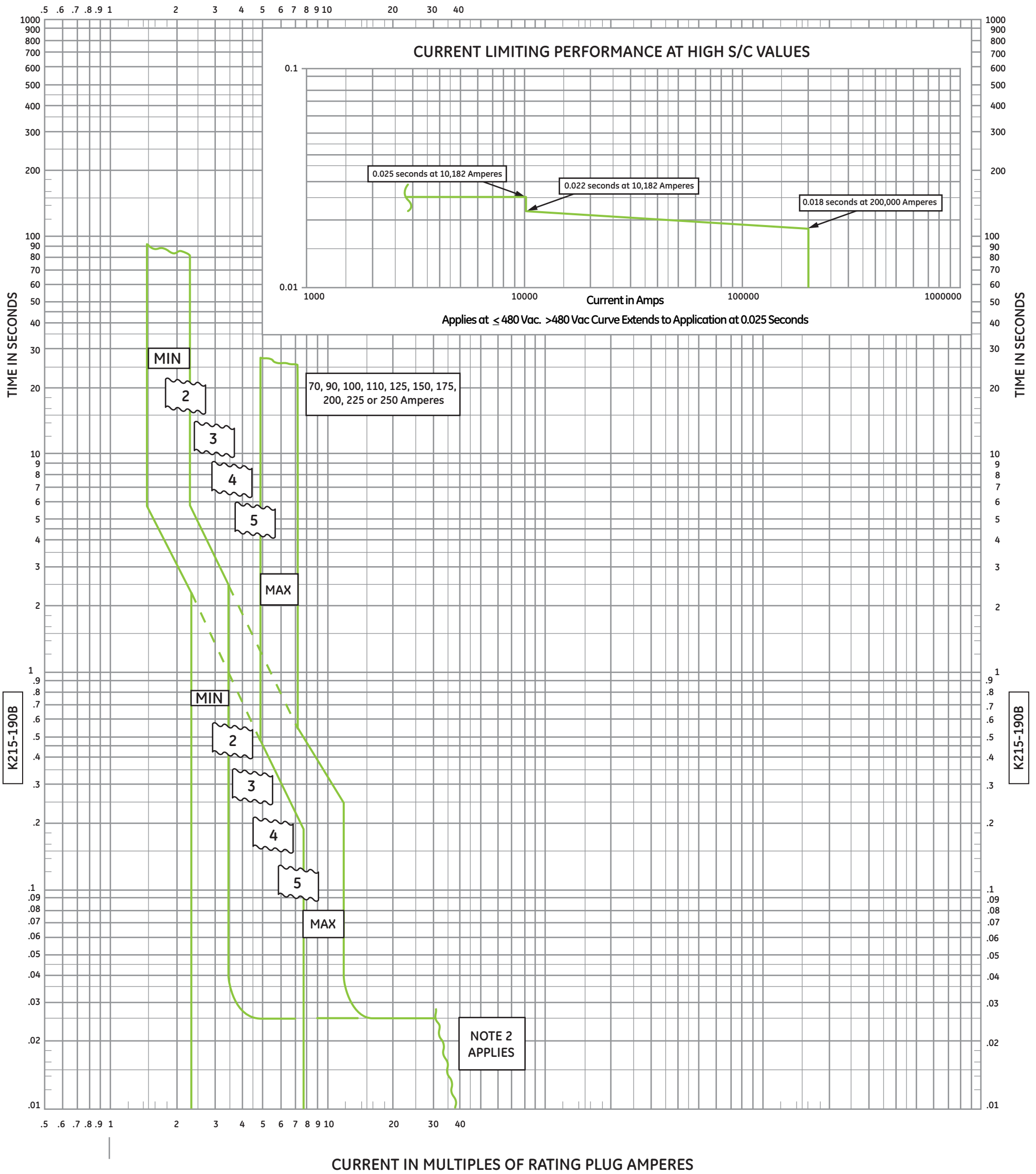

GE Consumer & Industrial -  
Electrical Distribution

**Current Ratings**

Frame Amperes	Rating Plug Amperes
250	70, 90, 100, 110, 125, 150, 175, 200, 225, 250

**Voltage Ratings**

2 Pole — 480 Vac max.  
3 Pole — 600 Vac max.

**MAG-BREAK® Motor Circuit Protector  
Type SF with Spectra RMS®  
Solid-state Trip**

Instantaneous  
with Tracking Short-time Delay  
Time-current Curves

Curves apply at 50 to 400 Hertz  
and from -20°C to 70°C breaker ambient

**K215-190B**

**Adjustments**

Instantaneous pick-up settings in multiples of rating plug rating: MIN, 2, 3, 4, 5, MAX

**Note 1:** Operation above 60 Hertz and 50°C play require thermal and interrupting derating of the circuit breaker. Refer to Selection and Application manual.

**Note 2:** Current limiting range, please refer to inset curve.