

# 400 Amp Pedestal Metering Equipment

If you have a home plus an outbuilding – a detached garage, workshop, studio, greenhouse or barn – Midwest Electric can help you deliver power to both! Our 400 amp pedestal meter can be installed freestanding or mounted directly onto the house or other structure.



- Open design and grade level markings (inside and out) make installation easy
- Panel access is easy for user and secure for utility
- Rated for both freestanding or surface mount installations
- Extra knockouts and four mounting holes mean less drilling
- Available with or without a pair of 200A circuit breakers
- NEMA 3R weatherproof enclosure
- G90 galvanized steel construction for superior corrosion protection
- Durable polyester powder coat finish resists chipping and fading



R400P6034

R455CP6034



# 400 Amp Pedestal Metering Equipment


## Specifications

- 120/240 Volts
- 400 Amp, 320 Continuous
- 3-Wire
- 10kAIC
- 4-Jaw Ringless Lever Bypass Meter Socket
- (2) 200 Amp Breakers Installed (R455CP6034 only)

## Wire Ranges

Connector	R400P6034				R455CP6034			
	Copper		Aluminum		Copper		Aluminum	
	Solid	Stranded	Solid	Stranded	Solid	Stranded	Solid	Stranded
Line	1/2" Stud Terminals							
Load	-	1-350	-	1-350	-	1-300	-	1-300
Neutral "A"	12-2	12-2	12-2	12-2	12-2	12-2	12-2	12-2
Neutral "B"	-	1-300	-	1-300	-	1-300	-	1-300
Neutral "C"	1/2" Stud Terminals							

## Dimensions

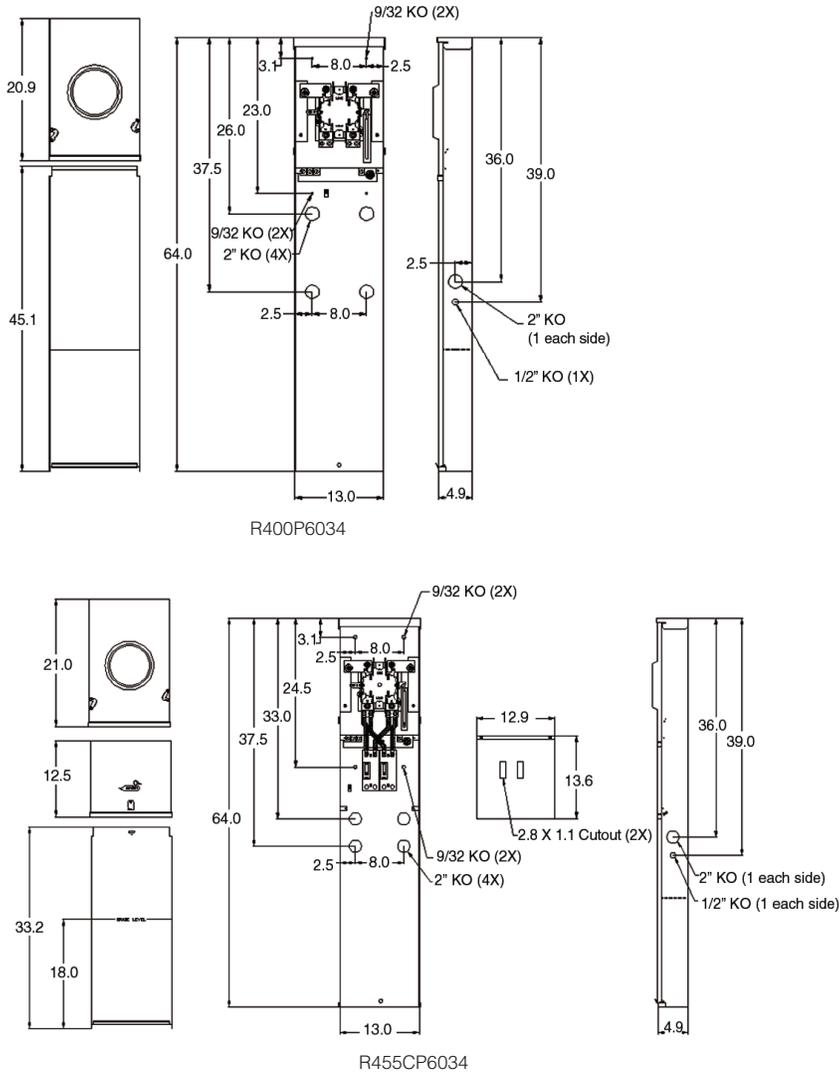

Information provided is subject to change without notice. Please verify all details with Midwest Electric Products. All values are design or typical values when measured under laboratory conditions, and Midwest makes no warranty or guarantee, express or implied, that such performance will be obtained under end-use conditions.

Midwest Electric Products  
 305 Gregson Drive  
 Cary, NC 27511  
 Customer Service: 866-685-0577 • Fax: 804-965-1041  
[www.midwestelectric.com](http://www.midwestelectric.com)

© 2019 Midwest Electric Products

MET-015B (12/19)

