

METER MODULE

Installation and use of this equipment should conform to all local and national electrical codes and regulations.

Catalog No. TMP112320RTAB

TYPE 3R ENCLOSURE — RAINPROOF


MAIN BUS — 1200 AMPS. MAX.
120/240 VAC 1 PH. — 3W
208Y/120 VAC 3 PH. — 4W

Use only GENERAL ELECTRIC
Type TQD, THQD, TMQV, TEB,
TED, or THED Circuit Breakers.

BRANCH BREAKERS: 225 Amp Max.
Meter Socket Rating: 200 Amp Continuous

Use with TMP Main Switch,
Main Breaker, Main Lug,
or Meter Modules.

Meets EUSERC

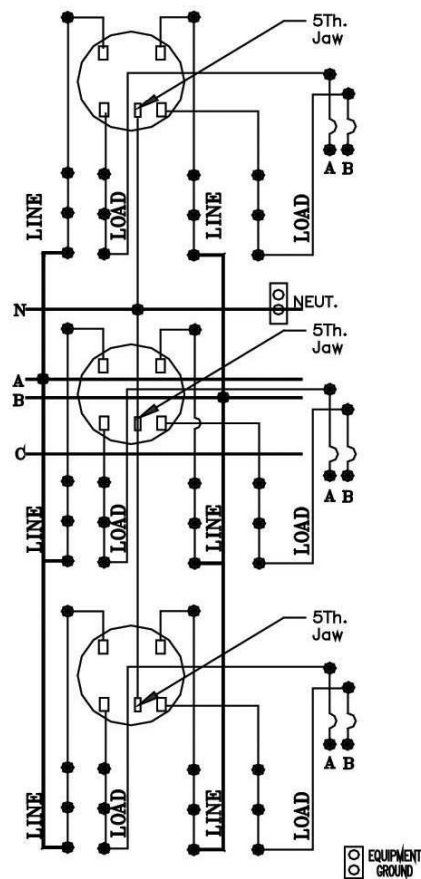

TYPICAL DIAGRAM

SUITABLE FOR USE AS SERVICE EQUIPMENT
WHEN USED WITH TMP MAIN LUG MODULES AND
WHEN NOT MORE THAN SIX MAIN DISCONNECTING
MEANS ARE PROVIDED.

**TORQUE MAIN BUS JOINT
BOLTS 25 LBS-FT. (300 LBS-IN)**

USE 60/75°C AL. OR CU. WIRE

LUG SPECIFICATIONS

Function	Wire Size Cu-Al AWG/MCM	Torque Lb.-ins.	
Neutral	(2) 1/0-300	200	
Equipment Ground	(2) {	14-10	35
		8	40
		6-4	45
		3-2/0	50

Torque Breaker Lugs to value specified on breaker.

RAINTIGHT HUBS

Conduit Size	Catalog No.
1/2	343L647G3
3/4	343L647G4
1	343L647G5
1-1/4	343L647G6
1-1/2	343L647G7
2	343L647G8
2-1/2	343L647G9
3	343L647G10
3-1/2	343L647G11
4	343L647G12

Suitable for Top or Bot. feed. For Top feed order
Raintight Hubs from table above.

REPLACEMENT PARTS

TENANT BREAKER COVER	TMBC20
BREAKER MOUNTING KIT	TMTQD3
HARDWARE KIT	TMP3SK

GENERAL  ELECTRIC