


Circuit Breaker Time/Current Curves

GE TMQL/TMQA 2-Pole Circuit Breakers, 15-125 Amperes

For application and coordination purposes only. Based on 40°C ambient, cold start. Connected with four (4) feet of rated wire (60/75°C up to 100 amp, 75°C for 125 amp) per terminal. Tested in open air with current in all poles.

Breaker Ratings (UL Listed)

Breaker Type 2 Pole	Maximum Volts AC (60 Hz)	Continuous Amperes	Interrupting Capacity RMS Symmetrical Amperes (kA)
TMQL	120/240V	15-125A	42
TMQA	120/240V	15-125A	65

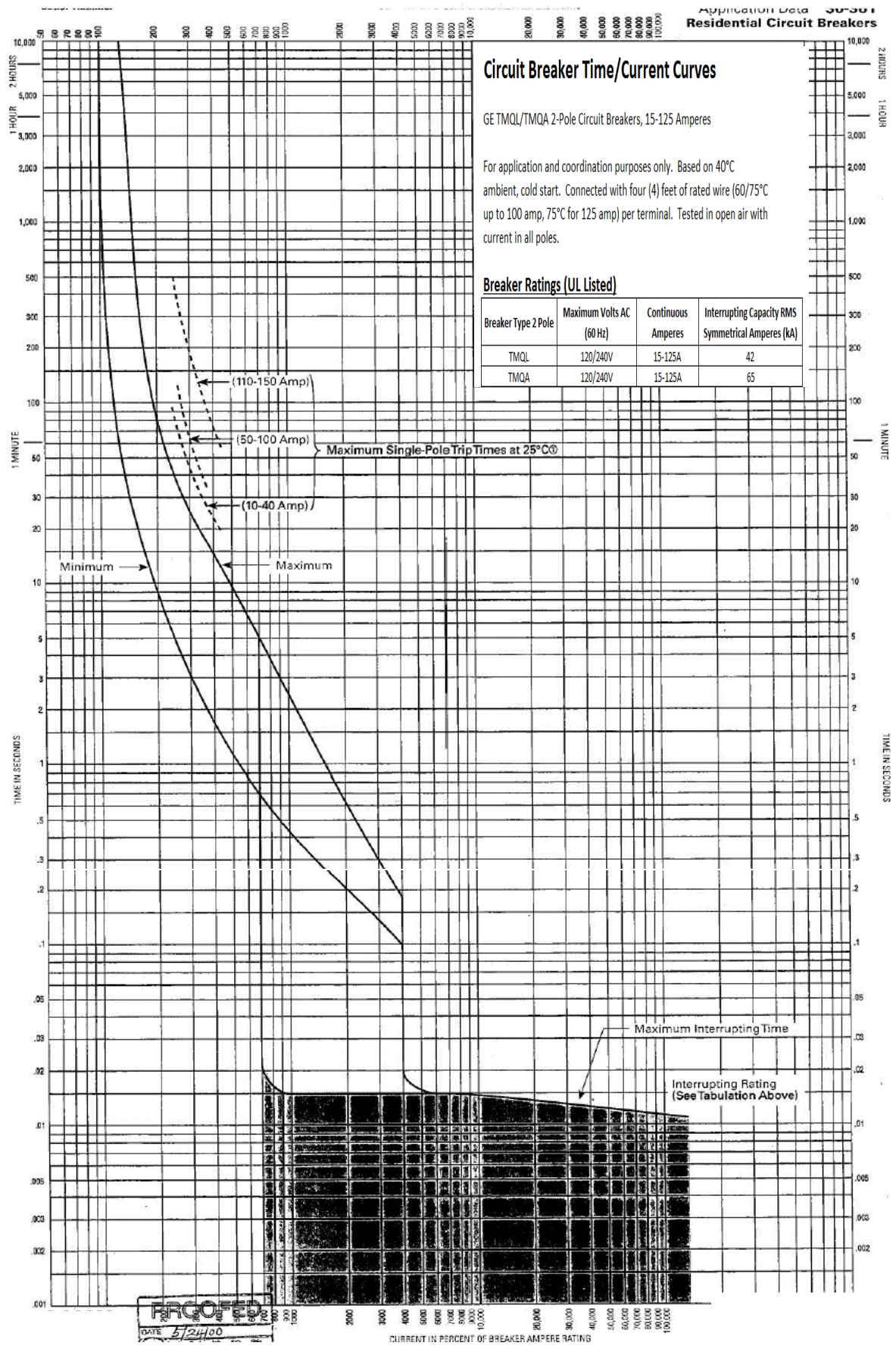

RECOPIED
DATE 5/24/00

CURRENT IN PERCENT OF BREAKER AMPERE RATING