


GE Dual Bulb Heater Fan

BH70DB Specifications

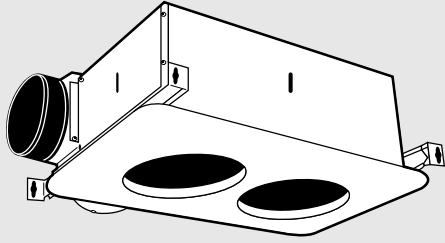

RATING

- 70 CFM / 3.5 sones @ 0.10" wg
- 120V, 4.6A, 60 Hz

GRILL

- White polymeric grill, flame retardant ABS (UL rated 94-5V) secured in place with torsion springs
- Dimensions: 15 3/4" x 10"

BLOWER WHEEL

- One-piece polymeric wheel
- 3 7/8" diameter, 2 1/2" wide, 21 fins

MOTOR

- Heavy-duty, plug-in, 2 pole
- Lifetime lubrication, thermally protected
- 120V, 60 Hz, 0.9A

FAN HOUSING

- 23 gauge galvanized steel
- Dimensions: 13 7/8" x 8" x 5 7/8"

DUCT COLLAR

- Plastic collar for 4" duct connection
- Built-in non-metallic back draft damper for quiet operation

LAMPING

- 2 x 250W maximum, Type R40 bulb, medium base, 1700 BTU heating

UNIT MOUNTING

- Rated Type IC for ceilings insulated to R-40 with at least 6" of clearance
- Maximum drywall thickness: 3/4"
- Rough-in opening: 13 15/16" x 8 1/16"
- Center between joists (with 16" centers) using hanging brackets

EFFECTIVE SQ. FT.

- Bathrooms: up to 70 square feet

SHIPPING

- Box dimensions: 18" x 11 1/2" x 7 3/4"
- Unit weight: 9 lbs.
- Cube: 0.93
- Pallet: 48
- UPC: 7 83164 32937 7

STANDARDS

- UL-507 (Electric Fans)
- CSA C22.2 No. 113 (Fans & Ventilators)
- HVI Certified (Standard 916 Air Flow Test & Standard 915 Procedure for Loudness Rating of Residential Fan Products)



HVI PERFORMANCE DATA

	Static pressure (inches of wg)								
	0	0.05	0.1	0.15	0.2	.025	.03	.035	.04
CFM	77	74	71	68	65	61	57	52	45
RPM	2300	2400	2450	2500	2550	2600	2650	2710	2840
Watts*	552	553	552	551	551	550	548	547	545

* Includes two heat lamp bulbs. For fan wattage only, subtract 500W.



GE Industrial Systems

General Electric Company
41 Woodford Avenue, Plainville, CT 06062
www.GEindustrial.com

© 2003 General Electric Company